


1. SPECIFICATION

AP-1205G-P3


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	<div><p>Standard state, standard drive circuit. Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	4 ~ 8	
03	Consumption Current	mA Max.	Mean: 50	
			Peak: 150	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	42±5	
06	Rated Frequency	Hz	2400	

REV NO.

REVISION NOTE

APPROVAL

DATE

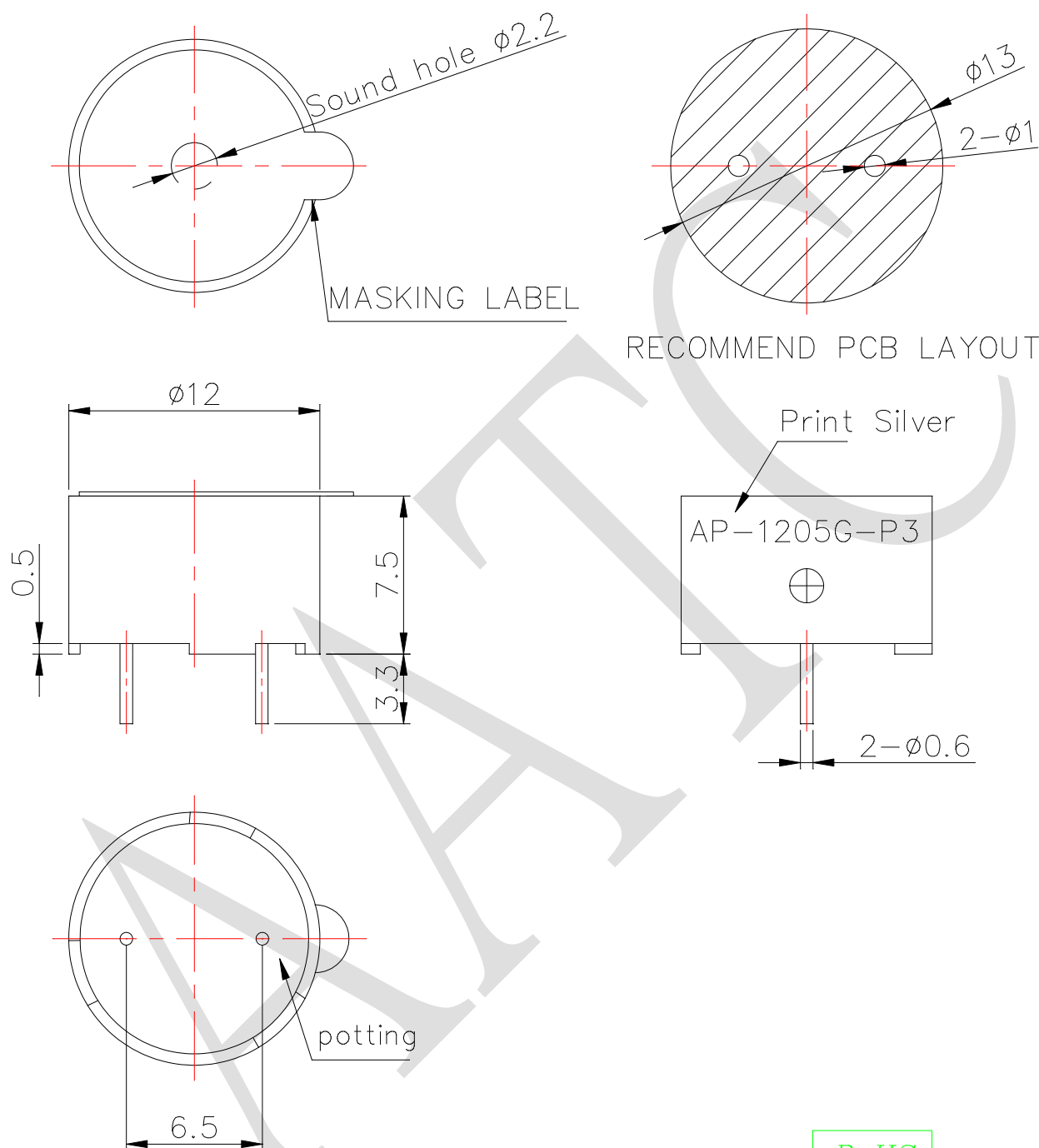

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Sunny 2015-9-29

SCALE: 4:1

SHEET: 1 of 1

PART NO. AP-1205G-P3

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE  $\pm 0.5$ 

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

DWG NO. FDC-120075F-05024R42-1

2

REV

MATERIAL: PBT



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AP-1205G-P3](#)