
 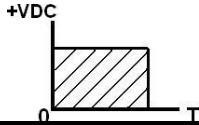

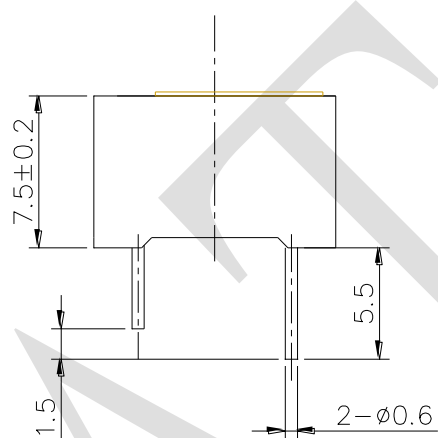


1. SPECIFICATION

AX-1205-P3-1

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	3 ~ 7	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	3100± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	85	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

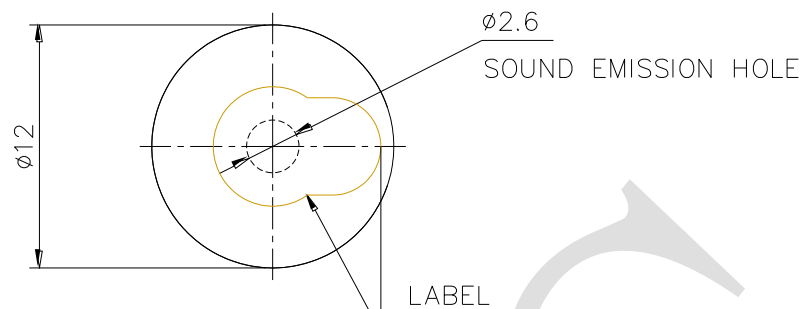


PRINT: Silver

AX-1205-P3



AX-1205-P3

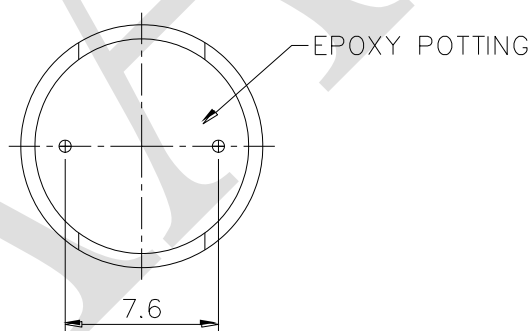

RoHS

TITLE: SOUND TRANSDUCER DIMENSIONS		DRAWN: Moose	2017/02/08	SCALE: 3/1	SHEET: 1 of 1
PART NO. AX-1205-P3-1	3	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. ***-*****		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED	
	REV	MATERIAL: NORYL		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPOATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1205-P3-1](#)