 


1. SPECIFICATION

AC-1005G-RPA-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	<div></div> <div>Standard state, standard drive circuit. Square wave 1/2 duty.</div>
02	Operating Voltage	V	4 ~ 6	
03	Consumption Current	mA Max.	60	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	40±4	
06	Rated Frequency	Hz	2730	

REV NO.

REVISION NOTE

APPROVAL

DATE

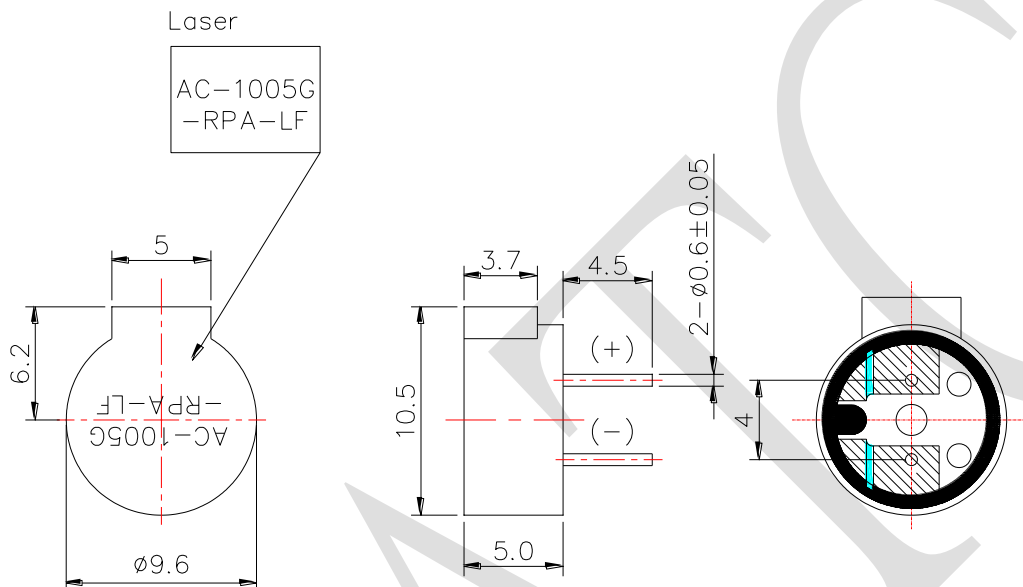

RoHS

TITLE: SOUND TRANSDUCER DIMENSIONS

DRAWN: Zack

2018/06/25

SCALE: 3/1

SHEET: 1 OF 1

PART NO. AC-1005G-RPA-LF

DESIGNED: R&amp;D OF AAT

UNITS: mm

CHECKED:

TOLERANCE  $\pm 0.5$ 

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

DWG NO. UGCM0905BPD

6

REV

MATERIAL: NORYL

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AC-1005G-RPA-LF