

## 1. Specifications

AX-1012(RoHS)






Items		Units	Specifications	Conditions
01	Rated Voltage	VDC	12.0	Response Time 0.5 Sec
02	Operating Voltage	VDC	9.0 ~ 15.0	Volts D.C
03	Consumption Current	mA (Max)	Mean 15	Applying rated voltage
			Peak 45	
04	Direct Current Resistance	Ohm	None	
05	Sound Output	dBA (min)	80	Distance at 10cm,applying rated voltage
06	Basic Frequency	Hz	2500± 200	

REV NO.

REVISION NOTE

APPROVAL

DATE

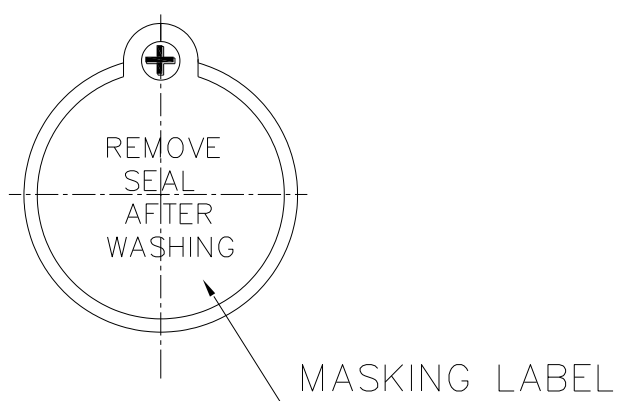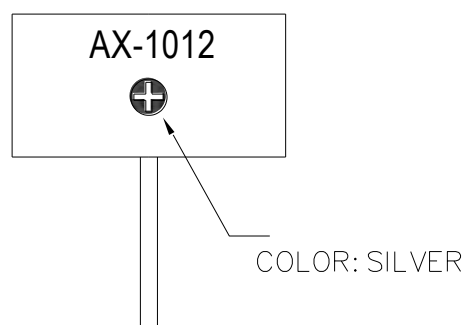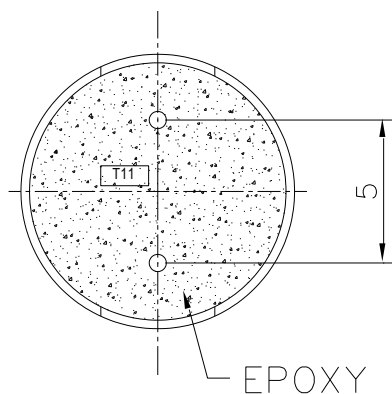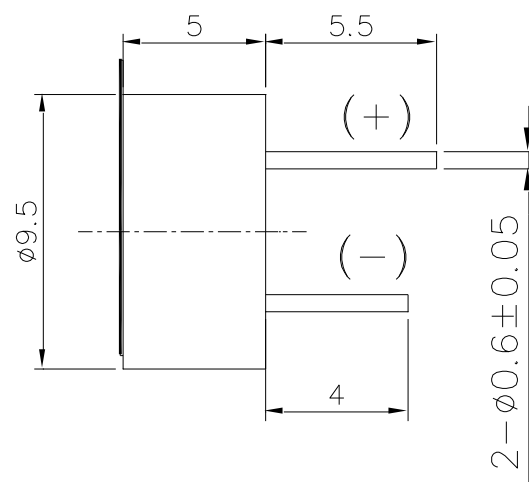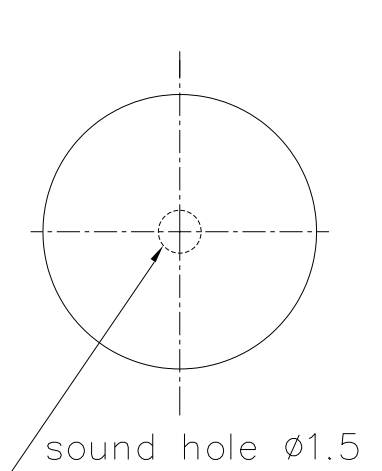

TITLE: SOUND TRANSDUCER DIMENSIONS

DRAWN: TOM 2008/12/10

SCALE: 1:1 SHEET: 1 : 1

PART NO. AX-1012

DESIGNED: R &amp; D OF AAT

UNITS: mm

CHECKED:

TOLERANCE  $\pm 0.5$ 

DWG NO. XD-1053

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

REV

MATERIAL: Black PBT



苙翔科技股份有限公司  
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1012](#)