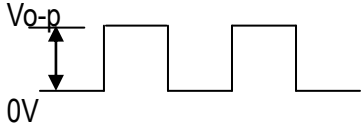


1. Specifications

AC-901N-RPB-LF (RoHS)



Items		Units	Specifications		Conditions
01	Rated Voltage	Vo-p	1.5		
02	Operating Voltage	Vo-p	1.0~3.0		
03	Consumption Current	mA (Max)	Mean	60	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak	180	
04	Direct Current Resistance	Ohm	5.5±1		
05	Sound Output	dBA (min)	85		Distance at 10cm, applying rated voltage, rated frequency square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	3200		

REV NO.

REVISION NOTE

APPROVAL

DATE

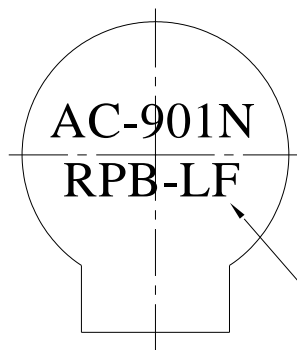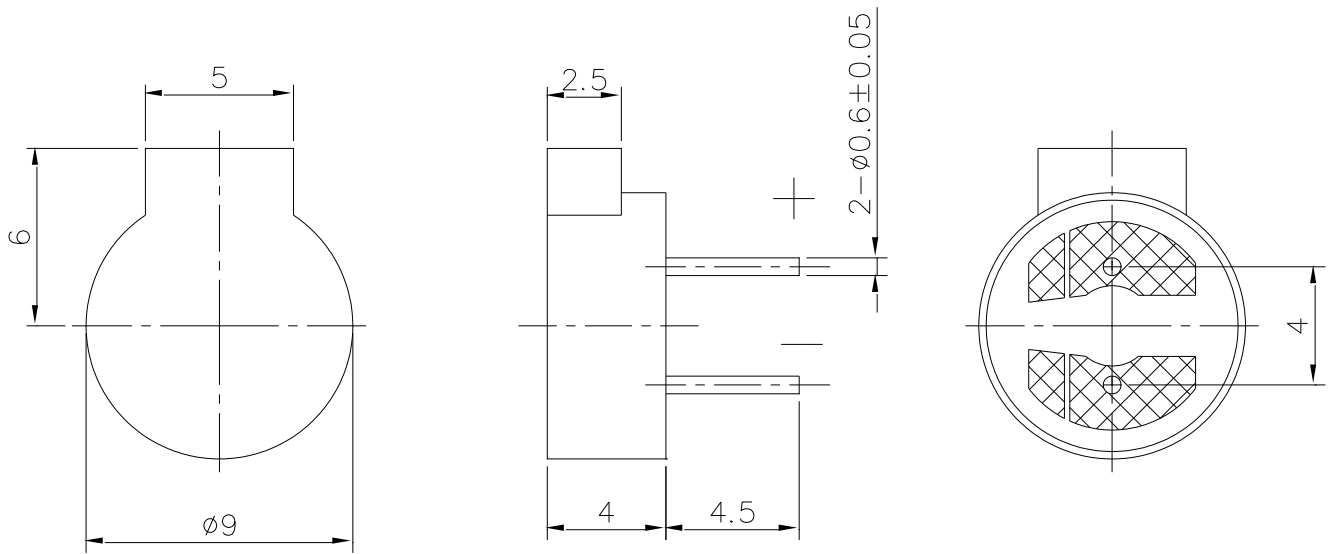

COLOR:SILVER

TITLE: SOUND TRANSDUCER

DRAWN: Jason

2009/10/06

SCALE: 4:1

SHEET: 1 of 1

PART NO. AC-901N-RPB-LF

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

DWG NO. HS-091006

REV

MATERIAL: NORYL

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AC-901N-RPB-LF](#)