
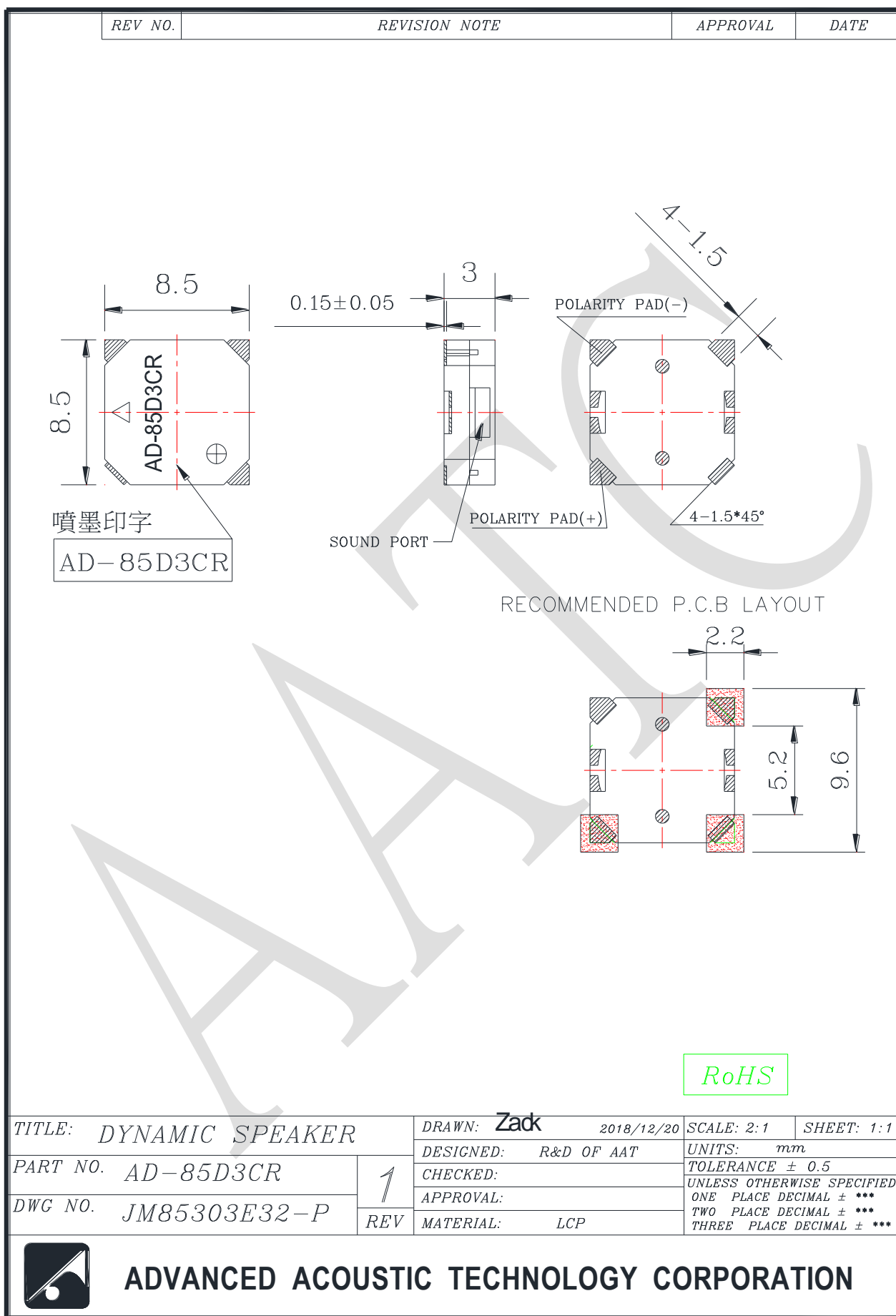


1. SPECIFICATION

AD-85D3CR

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.3	<div>A square wave diagram with a peak-to-peak voltage labeled Vp-p and a baseline labeled 0V.</div> <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	2.5 ~ 5.0	
03	Consumption Current	mA Max.	80	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	83	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	32±5	
06	Rated Frequency	Hz	2700	



For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AD-85D3CR](#)