 


1. SPECIFICATION

AC-1001N-RPB-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	 <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA Max.	80	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	88	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	5.5 ± 1.0	
06	Rated Frequency	Hz	2730	

REV NO.

REVISION NOTE

APPROVAL

DATE

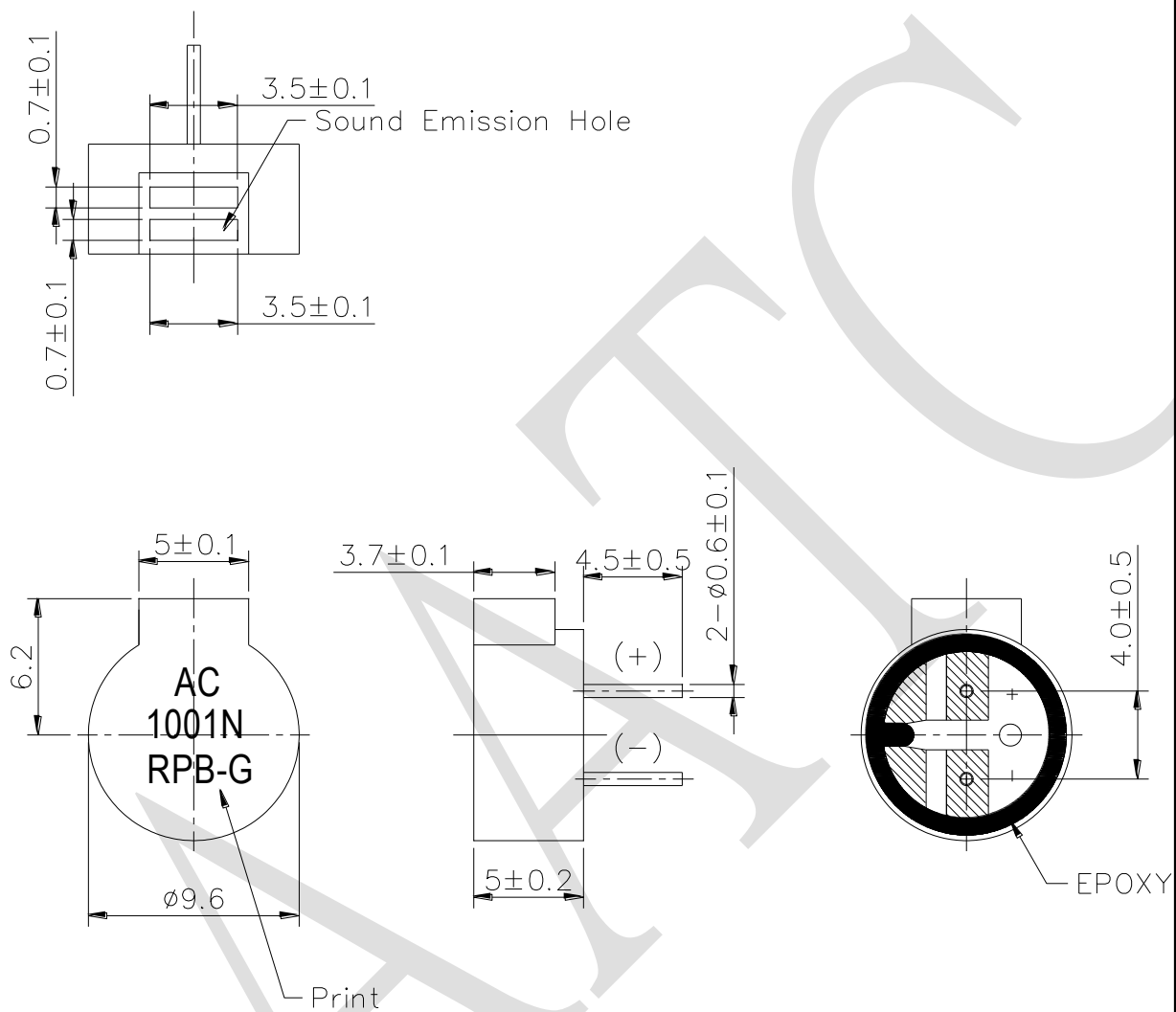

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Zack

2017/05/25

SCALE: 4:1

SHEET: 1 of 1

PART NO. AC-1001N-RPB-LF

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. SHQ1001QL

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1001N-RPB-LF](#)