 



1. SPECIFICATION

AC-12L3A

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	<div></div> <div>Standard state, standard drive circuit. Square wave 1/2 duty.</div>
02	Operating Voltage	V	2 ~ 4	
03	Consumption Current	mA Max.	80	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	16±4	
06	Rated Frequency	Hz	2048	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

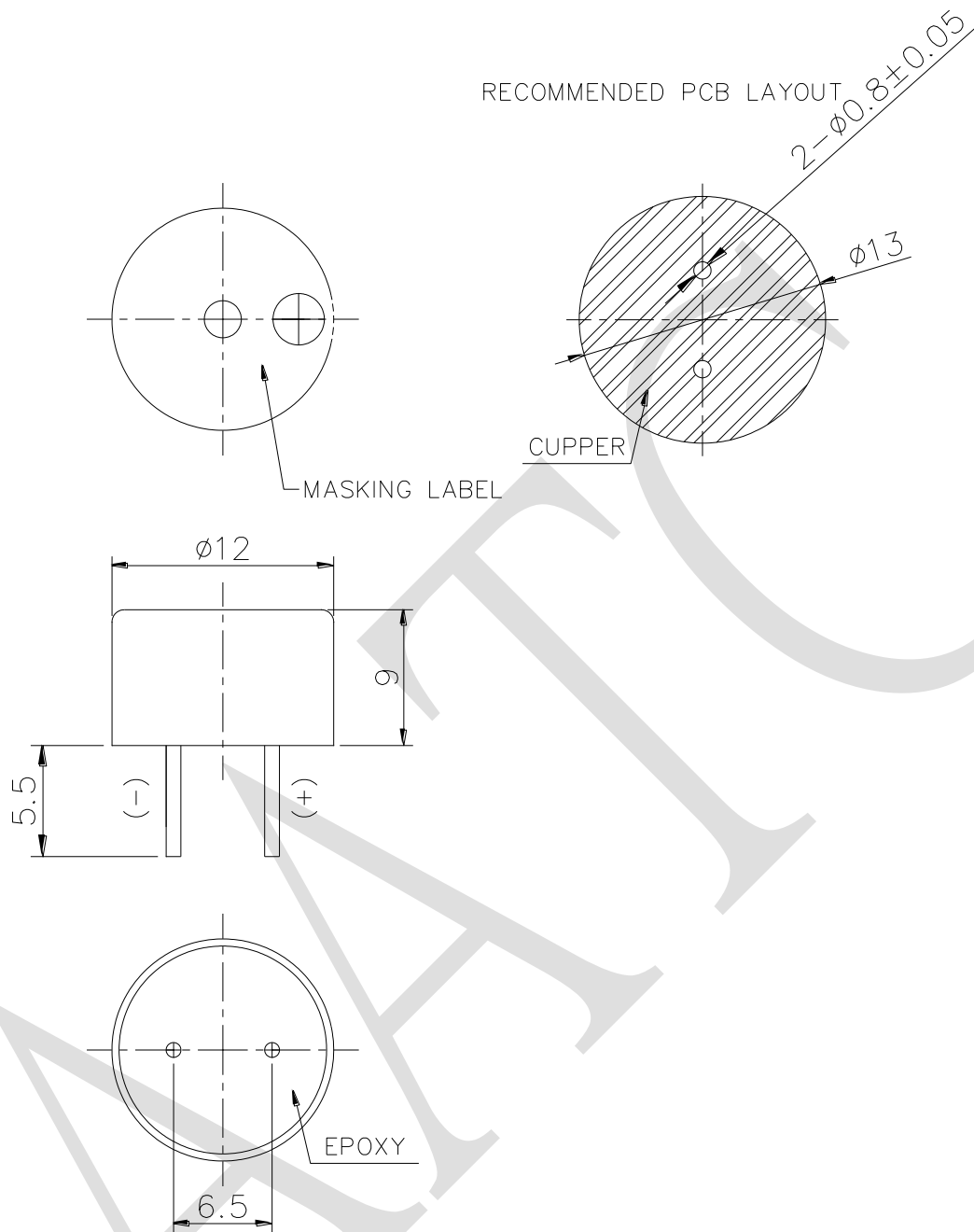

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: <b>Zadk</b>	2019/05/31	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-12L3A	1	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. ZDC-120090F03020R16		CHECKED:		TOLERANCE $\pm 0.5$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: PPO		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-12L3A](#)