 


1. SPECIFICATION

AS-1201B-F1-LF




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	
02	Operating Voltage	V	1 ~ 3	
03	Consumption Current	mA (Max)	Mean : 15	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 45	
04	Direct Current Resistance	Ω	42 ± 6	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	4096	

REV NO.

REVISION NOTE

APPROVAL

DATE

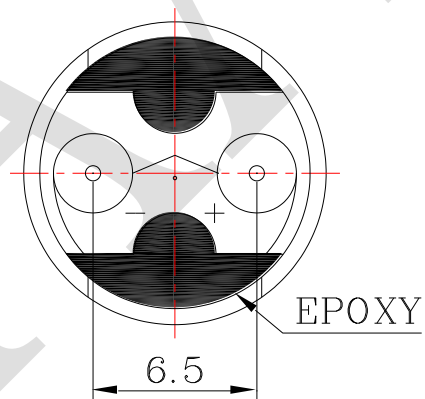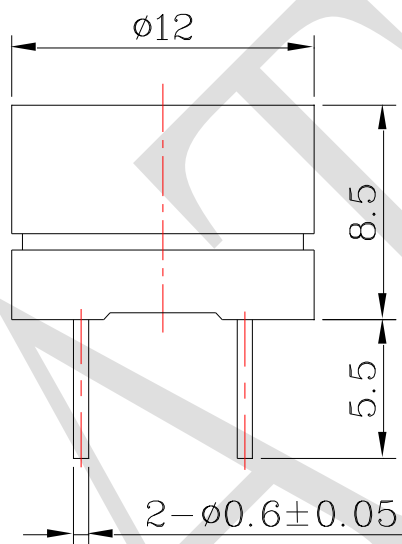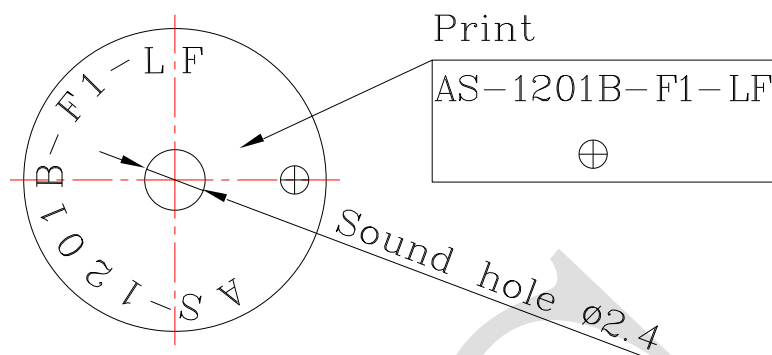

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Zack

2012/10/01

SCALE: 4:1

SHEET: 1 of 1

PART NO. AS-1201B-F1-LF

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGC12G-2PF

2

CHECKED:

APPROVAL:

TOLERANCE ± 0.5

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

REV

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AS-1201B-F1-LF