
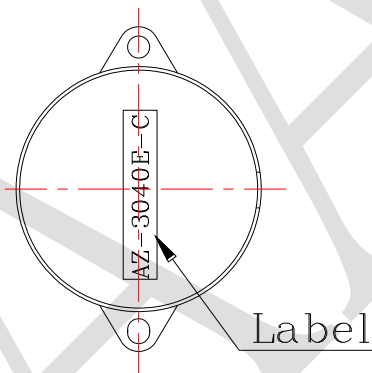
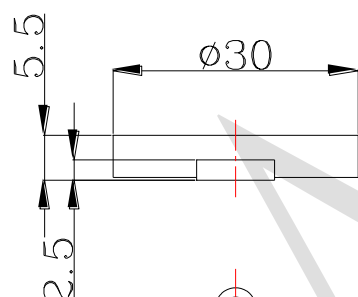


1. SPECIFICATION

AZ-3040E-C

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1~ 30	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	85	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000± 500	Rated Voltage
06	Capacitance	pF	25000±30%	At120Hz

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

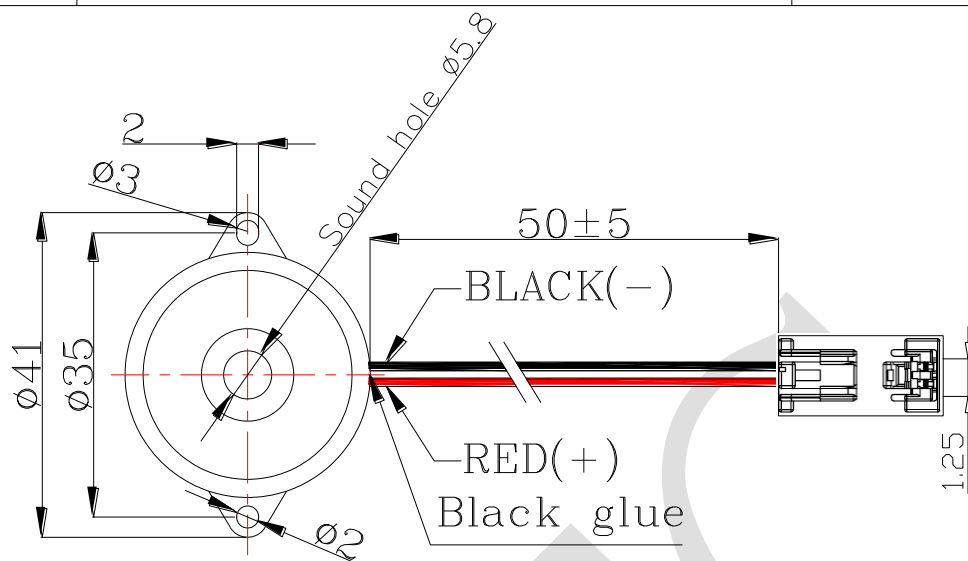

Wire: UL 1061.AWG28#
Terminal:TYU TU1211TP0-A
Housing:TYU TU1211HNO-1×02K

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zadk	2016/12/20	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-3040E-C</i>		DESIGNED: <i>R&D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. <i>UGPA30F4003WC50</i>		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>ABS</i>		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-3040E-C](#)