

1. SPECIFICATION

AZ-1340E-P13


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.0	Vp-p (Square Wave) 1/2 duty
02	Operating Voltage	V	1~ 30	
03	Rated Current	mA(Max)	5	Rated Voltage
04	Sound pressure level (Distance at 10cm)	dBA(Min)	75	Rated Voltage Rated Frequency
05	Resonant Frequency	Hz	4000± 300	Rated Voltage
06	Capacitance	pF	15000±30%	At 120Hz

REV NO.

REVISION NOTE

APPROVAL

DATE

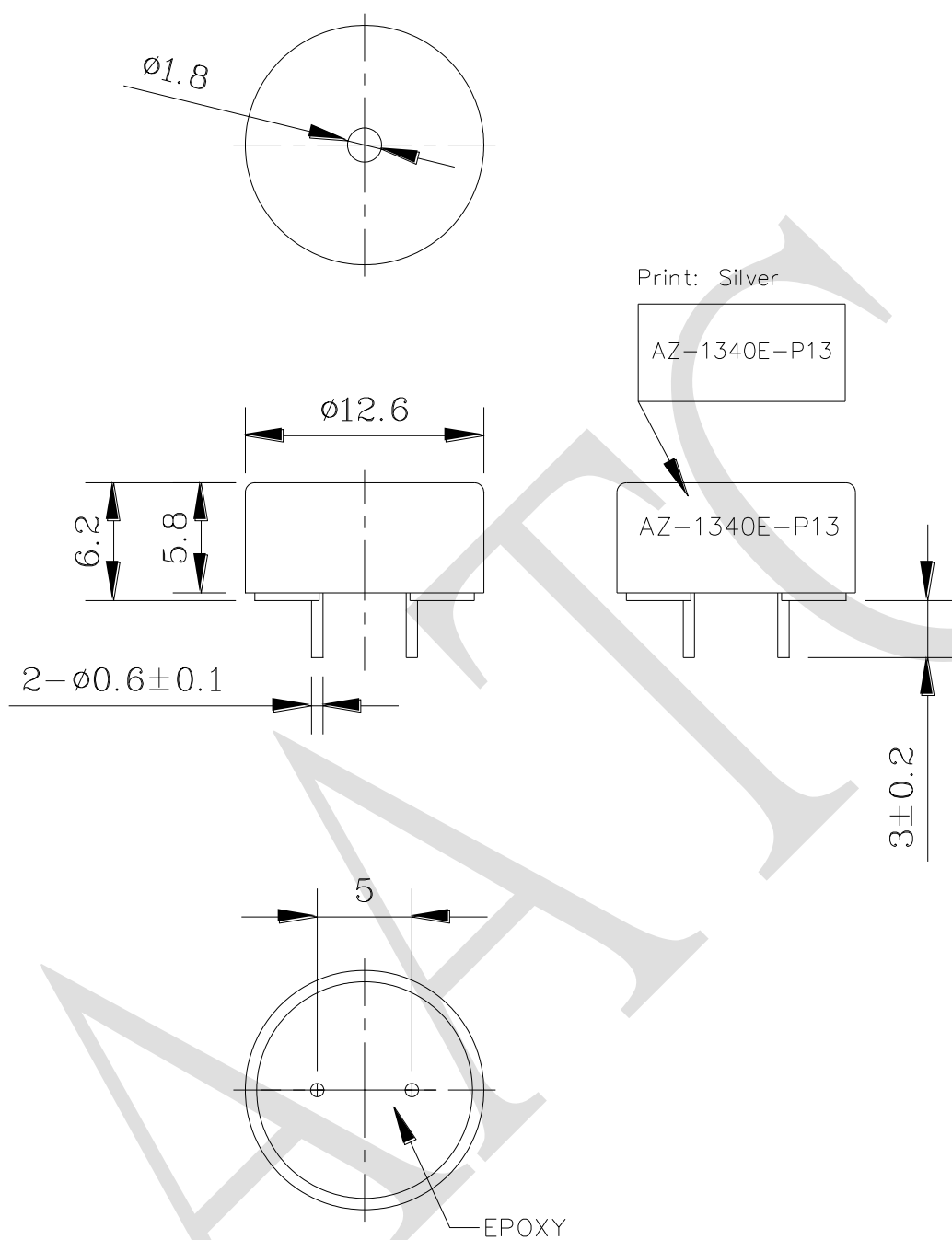

RoHS

TITLE: *PIEZO BUZZER*DRAWN: **Jerry**

2012/08/03

SCALE: 2:1

SHEET: 1:1

PART NO. *AZ-1340E-P13*DESIGNED: *R&D OF AAT*UNITS: *mm*DWG NO. *ZH-100415*

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

REV

MATERIAL: *PPO*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-1340E-P13