


1. SPECIFICATION

AC-903-D-1P

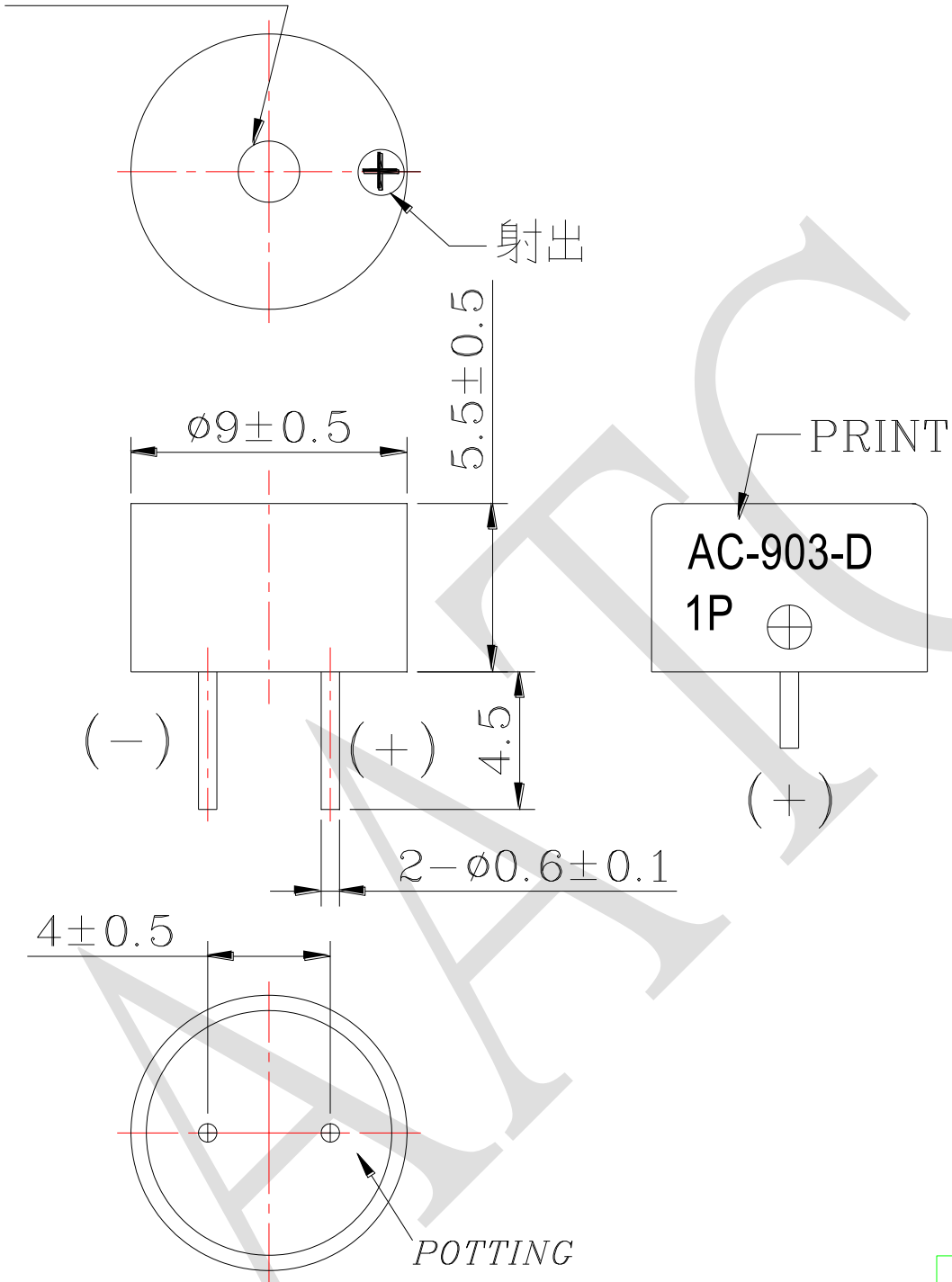
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.3	 <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	2 ~ 4	
03	Consumption Current	mA Max.	95	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	88	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	15 \pm 3	
06	Rated Frequency	Hz	3100	

REV NO.

REVISION NOTE

APPROVAL

DATE

SOUND HOLD $\phi 1.8$ 

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Moose	2016/06/28	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-903-D-1P	1	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. JM90553H15P		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: PBT		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-903-D-1P](#)