 


1. SPECIFICATION

AC-1205G-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	4 ~ 8	
03	Consumption Current	mA (Max)	Mean : 50	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 150	
04	Direct Current Resistance	Ω	40 ± 6	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2400	

REV NO.


REVISION NOTE

APPROVAL

DATE

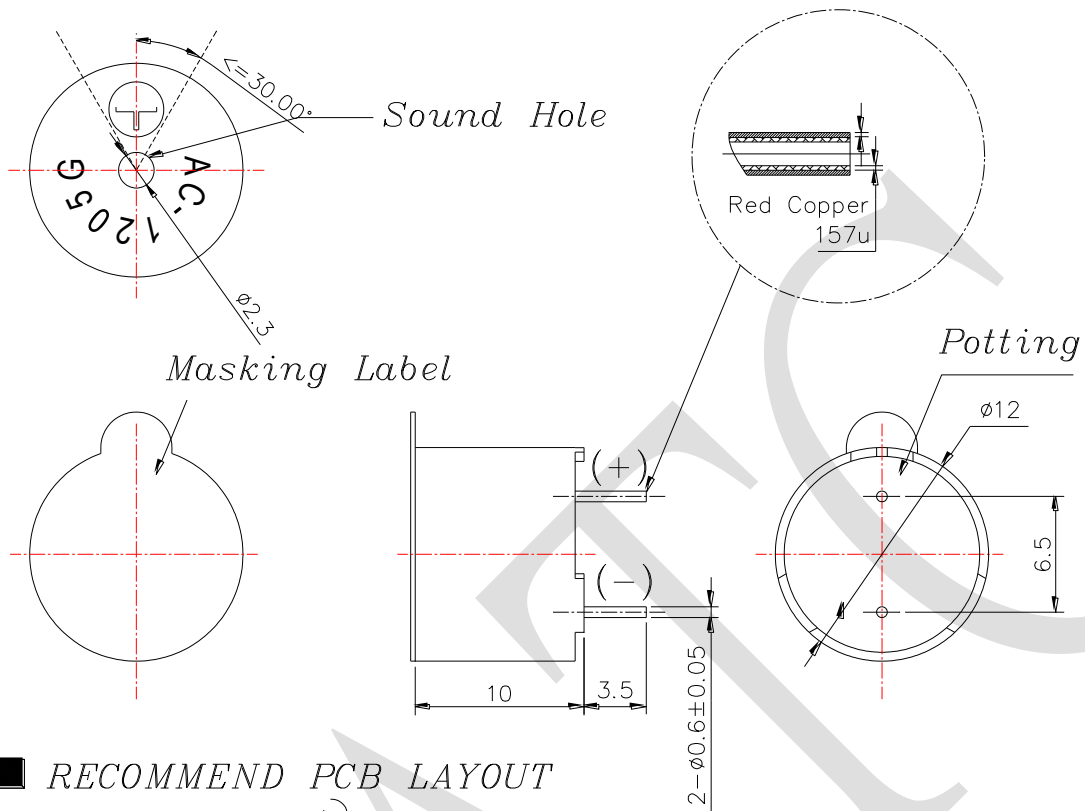

RECOMMEND PCB LAYOUT

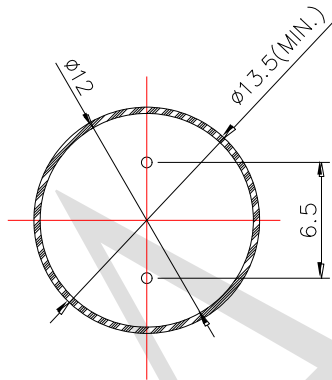

PART NO. DESCRIPTION.

A : COMPANY NAME
 C : MAGNETIC BUZZER
 |
 12 : DIAMETER
 05 : VOLTAGE
 G : RESISTANCE 40 ohm
 |
 LF : RoHS GRADE

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Moose 2017-10-17

SCALE: 4:1 SHEET: 1 of 1

PART NO. AC-1205G-LF

2

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

DWG NO. AC-1205G-LF

REV

MATERIAL: PBT

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1205G-LF](#)