


1. SPECIFICATION

AD-7504-LA1

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.6	
02	Operating Voltage	V	2.5 ~ 4.5	
03	Consumption Current	mA (Max)	Mean : 100	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 300	
04	Direct Current Resistance	Ω	16 ± 3	
05	Sound Output (Distance at 10cm)	dBA (Min)	80	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2900	

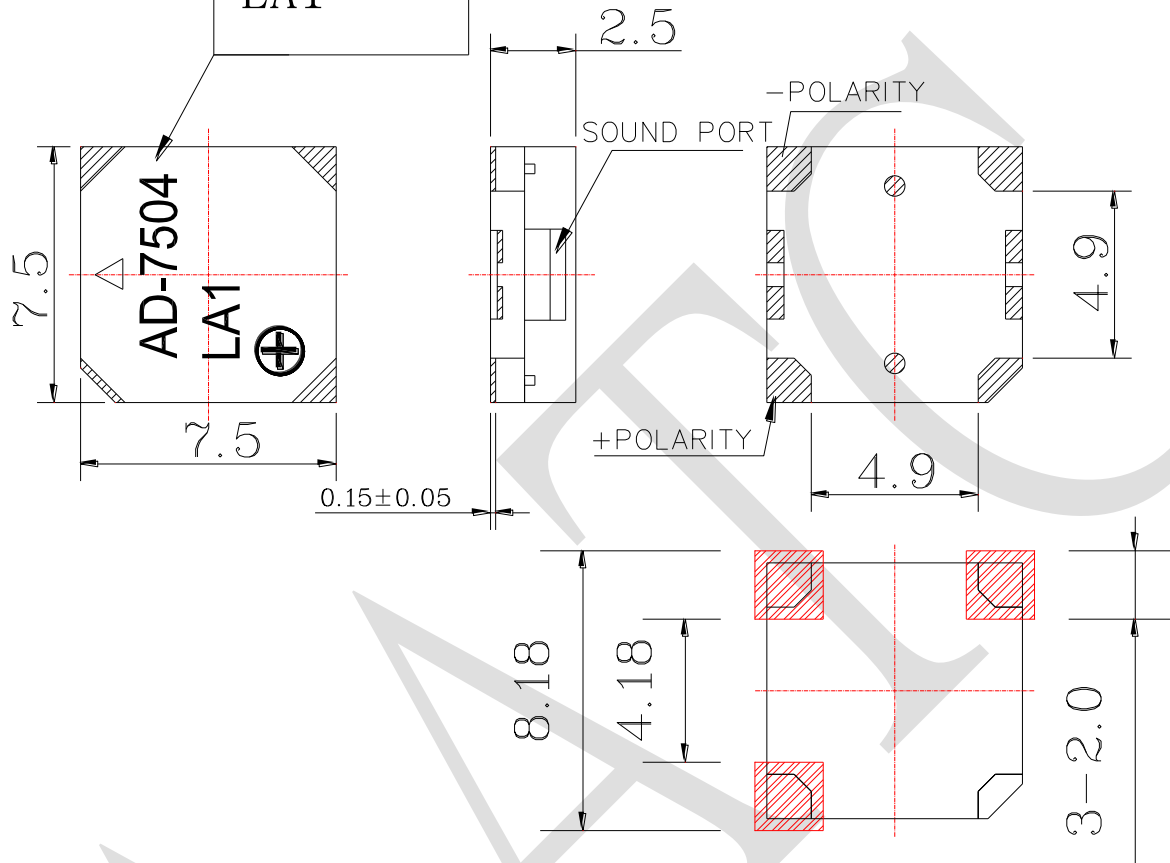
REV NO.

REVISION NOTE

APPROVAL

DATE

Print:

AD-7504
LA1

RECOMMENDED P.C.B. LAYOUT

RoHS

TITLE: SOUND TRANSDUCER (SMD)

DRAWN: Zack 2012/8/31

SCALE: 1:1 SHEET: 1 : 1

PART NO. AD-7504-LA1

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. SMD-075025H-03629

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

MATERIAL: LCP



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AD-7504-LA1](#)