 
 


1. SPECIFICATION

AZ-3235S-W-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	3 ~ 28	
03	Consumption Current	mA (Max)	10	Rated Voltage
04	Resonant Frequency	Hz	3500± 500	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	90	Distance at 30cm Rated Voltage / Resonant Frequency

REV NO.

REVISION NOTE

APPROVAL

DATE

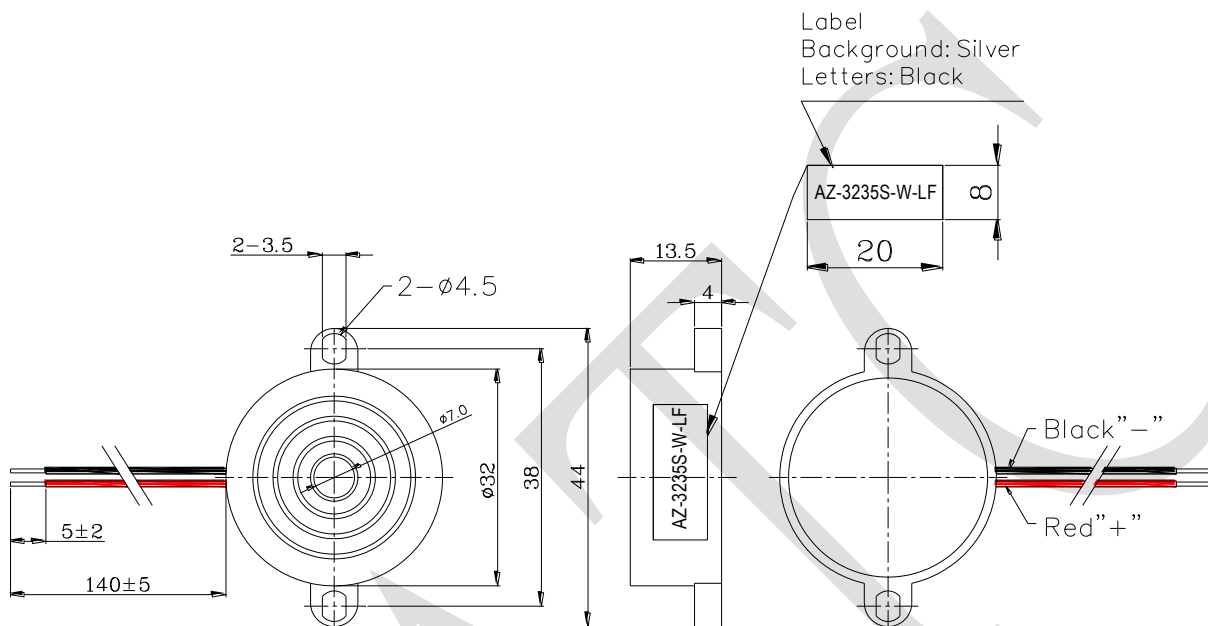

WIRE: UL1095, AWG28#

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zack	2012/10/17	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-3235S-W-LF</i>	4	DESIGNED: AAT	R&D	UNITS: mm	
DWG NO. <i>UGPA32BX3512W140</i>		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: ABS		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-3235S-W-LF