

1. SPECIFICATIONS

AMF-O60C40-NWH-LF

01	Electret's Type	Foil type
02	Sensitivity	-40±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	70 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥58dB


REV NO.

REVISION NOTE

APPROVAL

DATE




FILTER

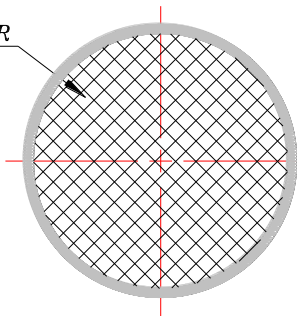

Wires: UL1571,30AWG#

Connector : Equivalent to Molex 51021-0200

Holder:DD-EQ-JTC79-01

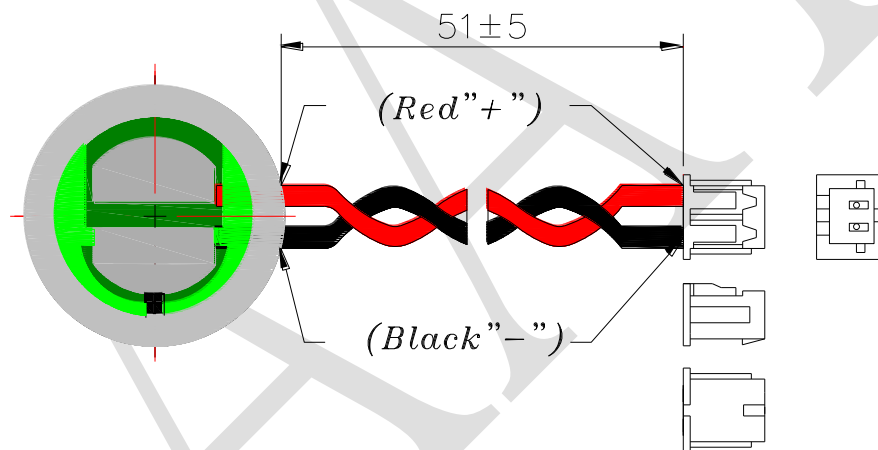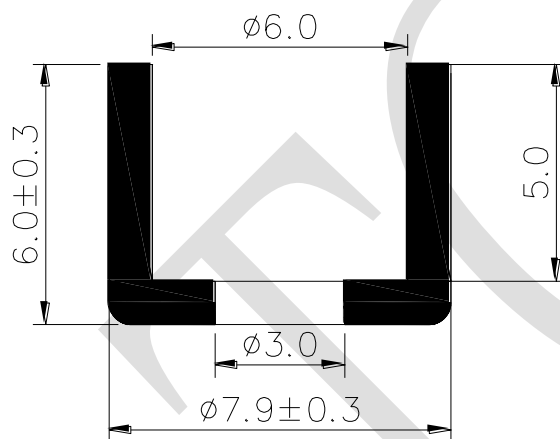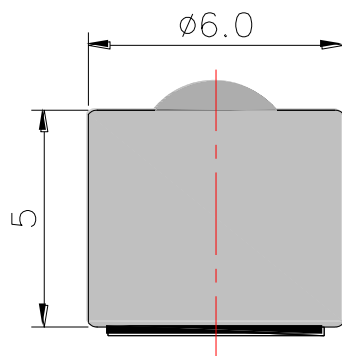

RoHS

TITLE: MICROPHONE

DRAWN: *Moose* 2016/03/11

SCALE: 5:1 SHEET: 1 of 1

PART NO. AMF-060C40-NWH-LF

DESIGNED: R & D OF AAT

UNITS: mm

DWC NO. F6050AL-SBN-D54-M -11436

2

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

MATERIAL: AL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AMF-O60C40-NWH-LF