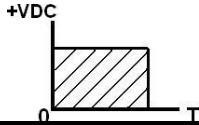
 


# 1. SPECIFICATION

AX-1003-P5

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 5	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	3100± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	80	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.

REVISION NOTE

APPROVAL

DATE

PRINT



AX-1003-P5




AX-1003-P5



(+)

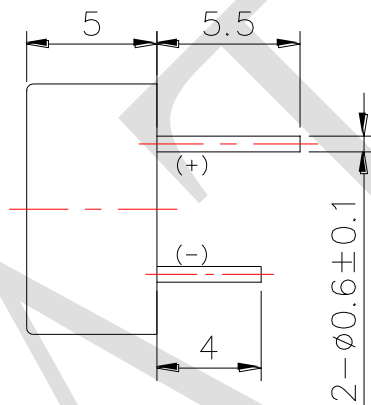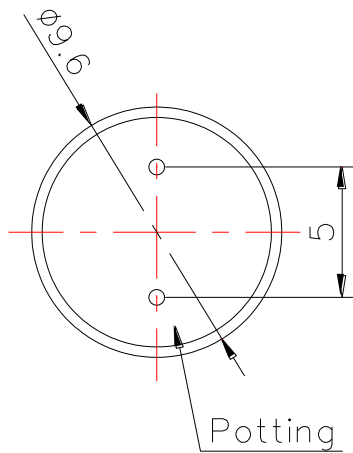

SOUND PORT Ø1.5

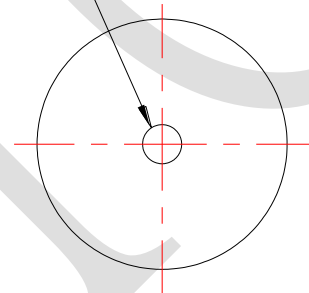

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Moose 2017/02/17

SCALE: 4:1 SHEET: 1 of 1

PART NO. AX-1003-P5

DESIGNED: R&amp;D OF AAT

UNITS: mm

DWG NO. FDM-2236 FDB-096050F-03031

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± \*\*\*

TWO PLACE DECIMAL ± \*\*\*

THREE PLACE DECIMAL ± \*\*\*

MATERIAL: PPO



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1003-P5](#)