
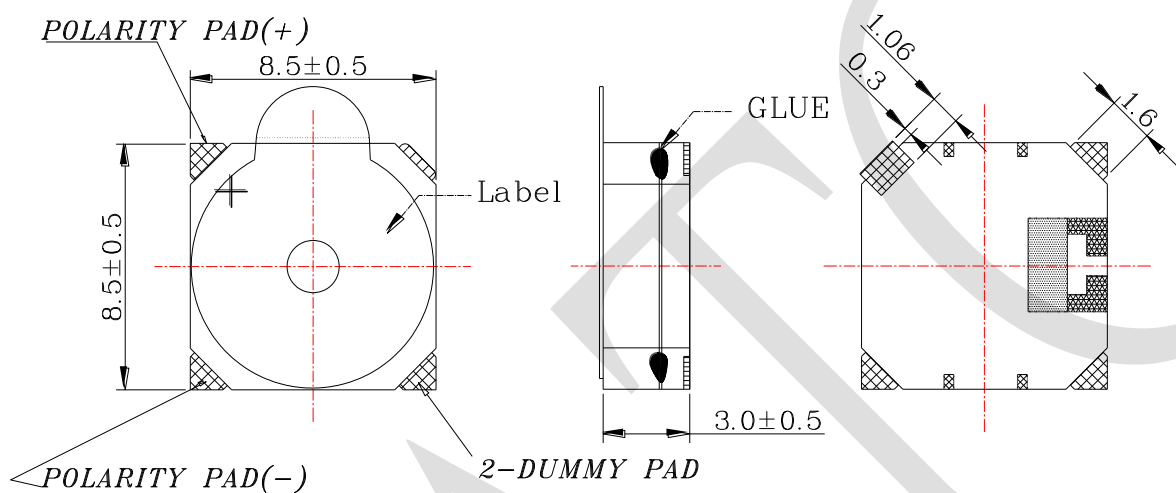


1. SPECIFICATION

AD-8504-CQ9-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.6	 <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	2.5 ~ 4.5	
03	Consumption Current	mA Max.	100	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	87	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	16±3	
06	Rated Frequency	Hz	2730	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Moose	2019-02-27	SCALE: 1:1	SHEET: 1 : 1
PART NO. AD-8504-CQ9-LF	4	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. UGCT8503CD4		CHECKED:		TOLERANCE $\pm 0.3$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: LCP		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AD-8504-CQ9-LF