


1. SPECIFICATION

AZ-1348E-6WV




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	10	<div><p>Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	1 ~25	
03	Consumption Current	mA (Max)	5	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	80	Rated voltage, rated frequency.
05	Capacitance	pF	14000±30%	At 120KHz
06	Rated Frequency	Hz	4800	

REV NO.

REVISION NOTE

APPROVAL

DATE

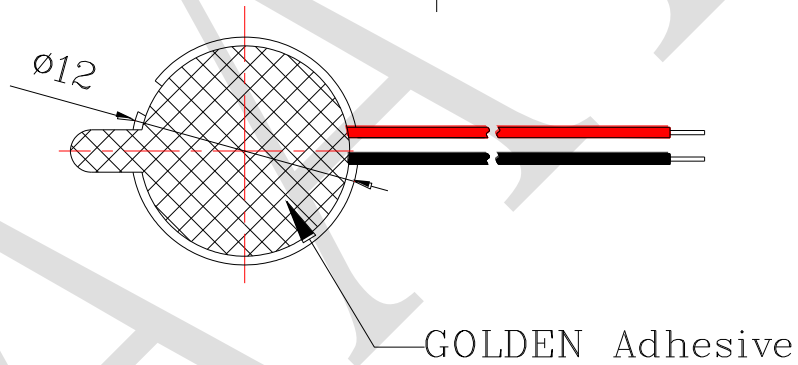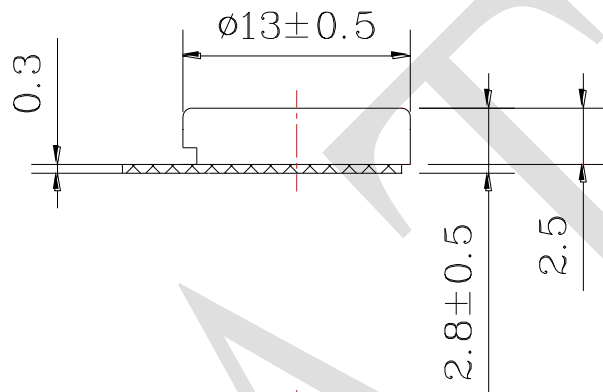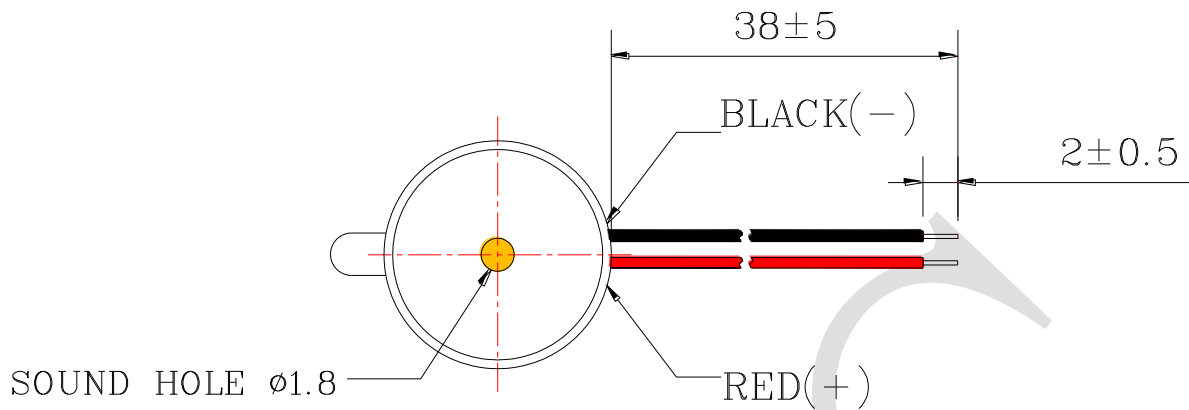

Wire: UL 1571.AWG32#

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Moose</i>	2019-02-26	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-1348E-6WV</i>		DESIGNED: <i>R&amp;D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. *****		CHECKED:		TOLERANCE $\pm 0.3$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>ABS</i>		ONE PLACE DECIMAL $\pm$ ***	
REV				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-1348E-6WV