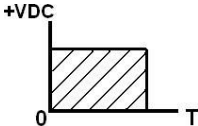
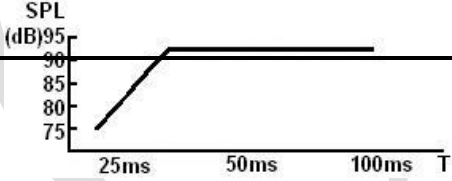


1. SPECIFICATION

AX-1201-P1-LF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	
02	Operating Voltage	V	1.2 ~ 3.0	
03	Consumption Current	mA (Max)	20	Rated Voltage
04	Sound pressure level	dB(A) (Min)	80	Distance at 10cm
05	Resonant Frequency	Hz	2400±100	

REV NO.

REVISION NOTE

APPROVAL

DATE

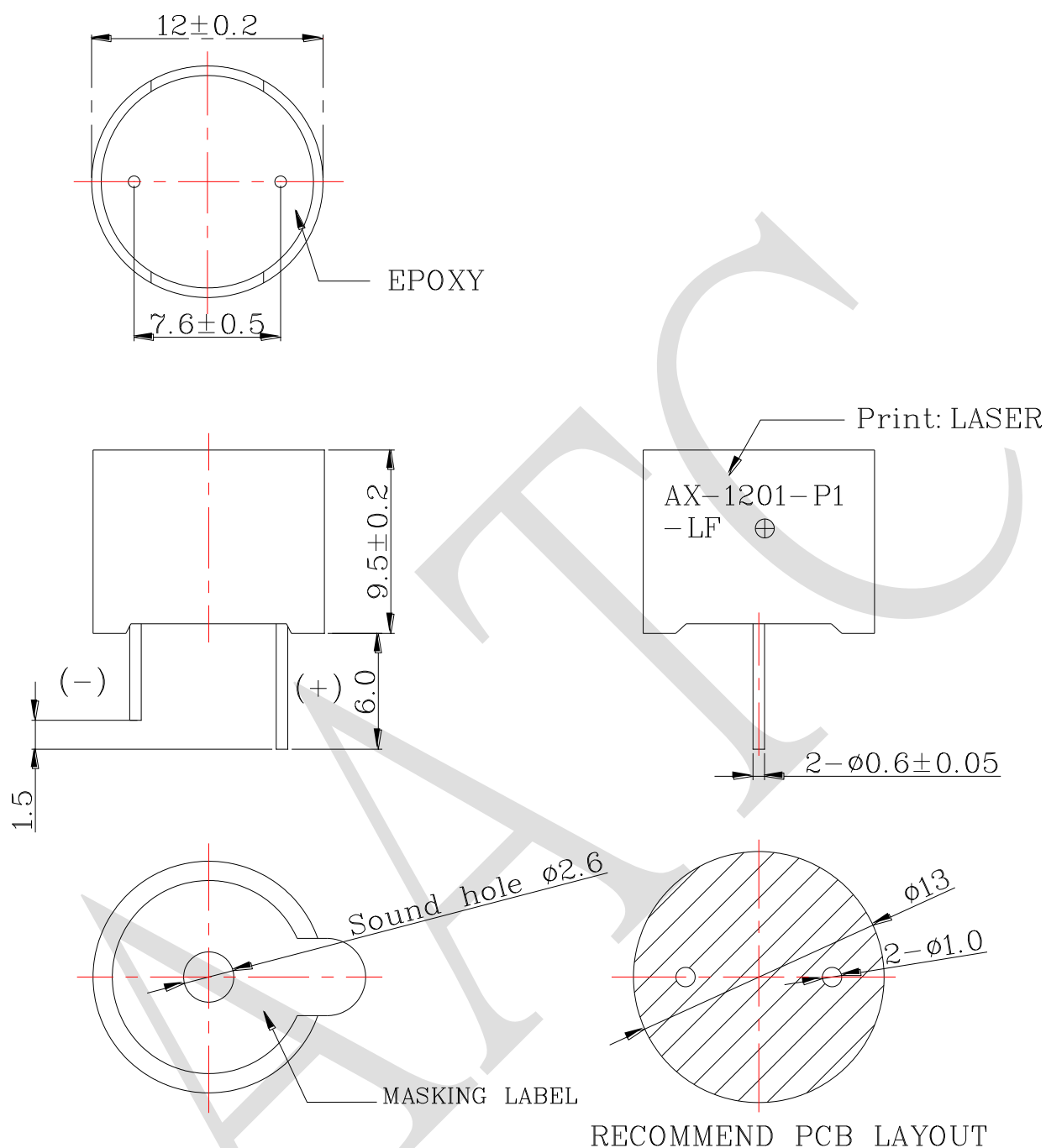

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Hank 2019/08/06 SCALE: 4:1 SHEET: 1 of 1

PART NO. AX-1201-P1-LF

DESIGNED: R&amp;D OF AAT

UNITS: mm

DWG NO. UGCM1201XPIC

3  
REV

CHECKED:

APPROVAL:

MATERIAL: PBT

TOLERANCE  $\pm 0.2$ 

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1201-P1-LF](#)