


1. SPECIFICATION

AC-1612J-PF


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	9 ~ 15	
03	Consumption Current	mA (Max)	Mean : 50	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 150	
04	Direct Current Resistance	Ω	115 ± 12	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	92	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2800	

REV NO.

REVISION NOTE

APPROVAL

DATE

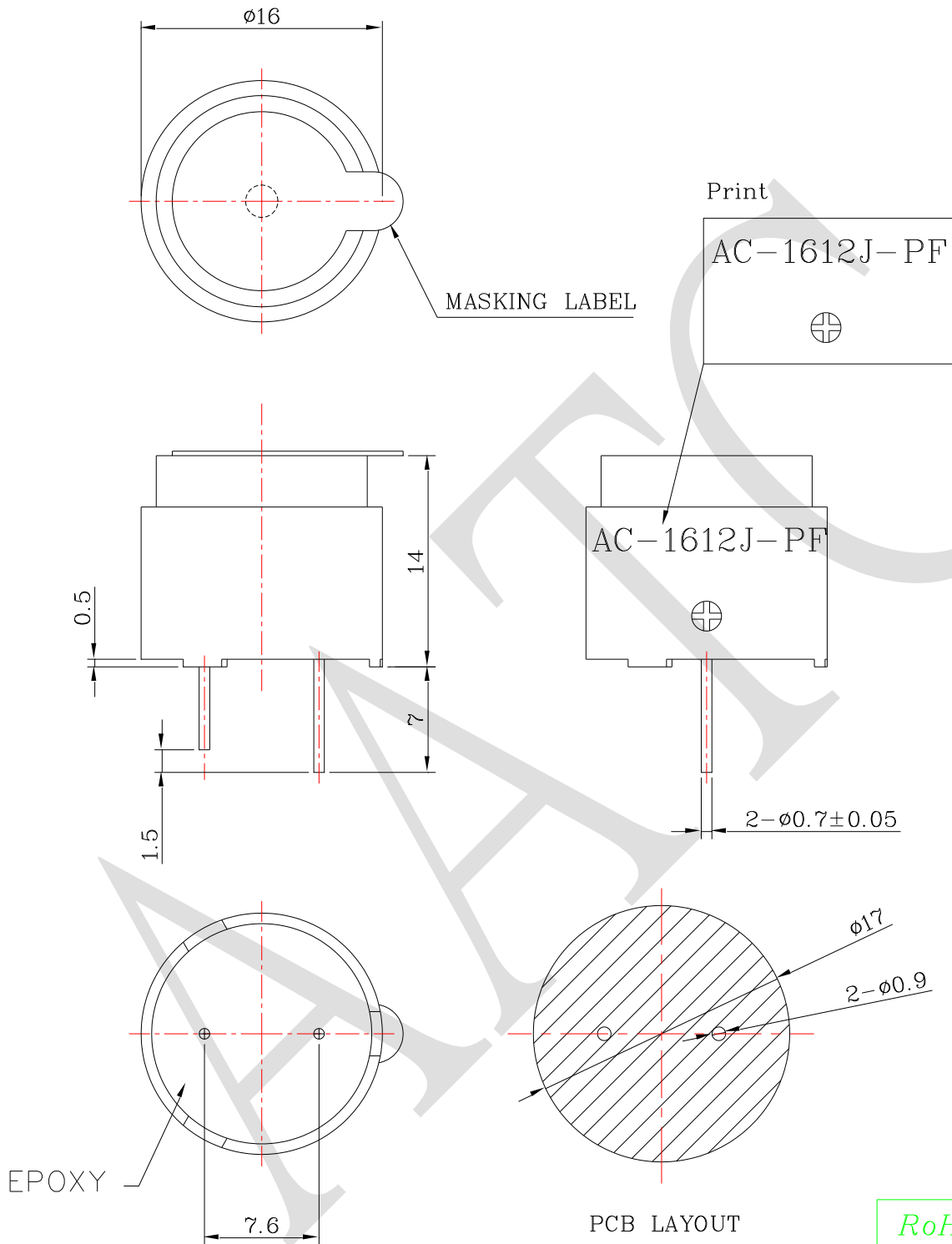

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: **Zadk** 2012/10/18

SCALE: 4:1 SHEET: 1 of 1

PART NO. AC-1612J-PF

DESIGNED: R&D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.5

DWG NO. UGCM1612APH-92

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1612J-PF](#)