 


1. SPECIFICATION

AC-9J5C2


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	 Standard state, standard drive circuit. Square wave 1/2 duty.
02	Operating Voltage	V	4 ~ 6	
03	Consumption Current	mA Max.	60	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	40 ± 4	
06	Rated Frequency	Hz	2731	

REV NO.

REVISION NOTE

APPROVAL

DATE

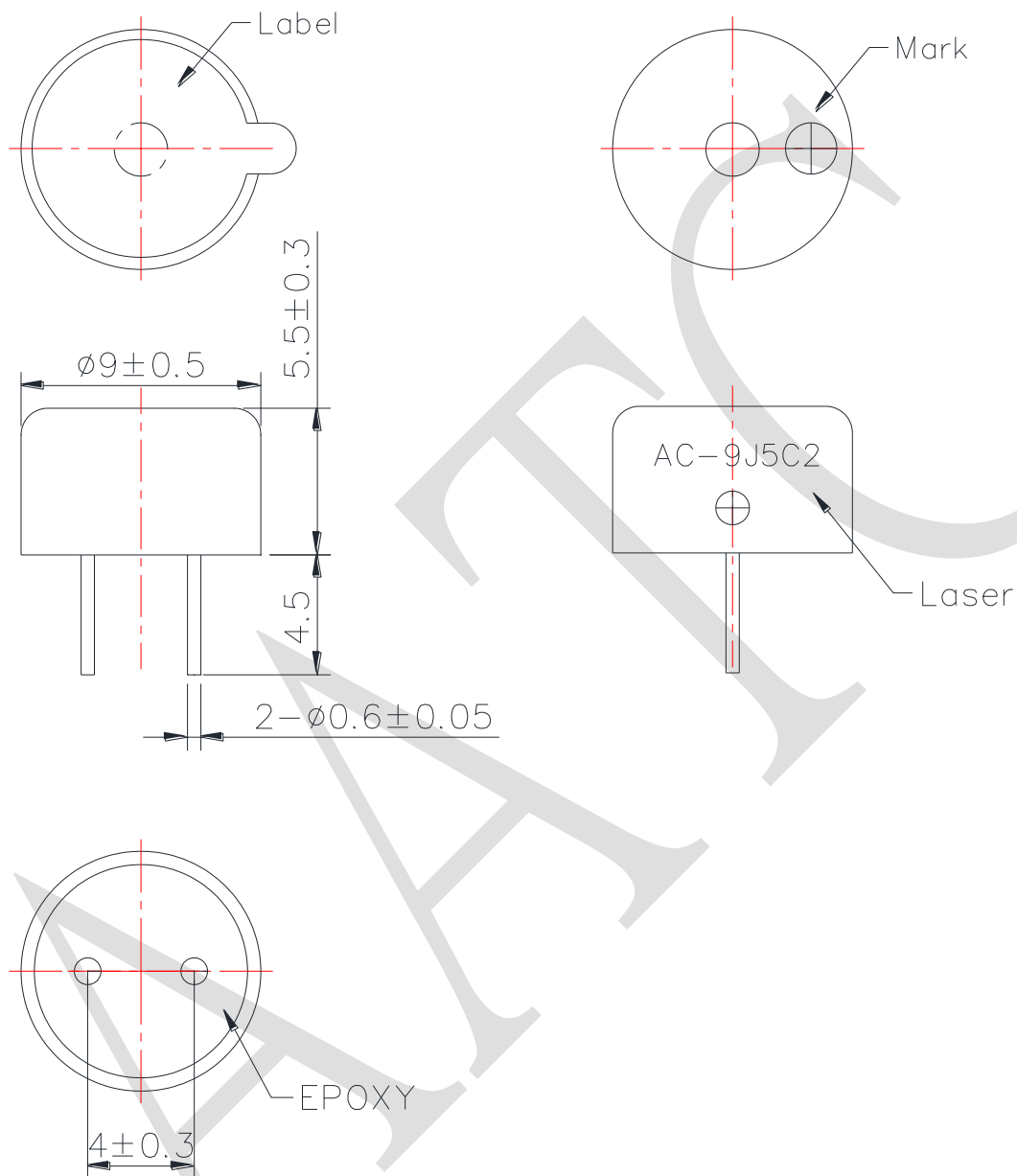

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Zack	2020/01/20	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-9J5C2		DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. UGCM0905EP4.5D		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: PBT		ONE PLACE DECIMAL \pm ***	
	1			TWO PLACE DECIMAL \pm ***	
	REV			THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-9J5C2](#)