

1. SPECIFICATIONS

AMB-O40J38-CWH-IP67

01	Electret's Type	Back type
02	Sensitivity	-38±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	100 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥ 58dB
11	Operating Temperature	-20~+70°C
12	Storage Temperature	-30~+70°C


REV NO.

REVISION NOTE



APPROVAL

DATE

Waterproof (White,IP67)

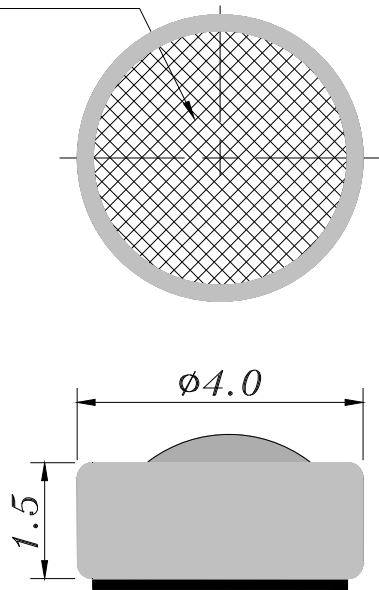

Wires: UL1571,32#AWG;
Connector:Molex 51021-0200 Equivalent .
Holder:DD-EQ-JTA49-07

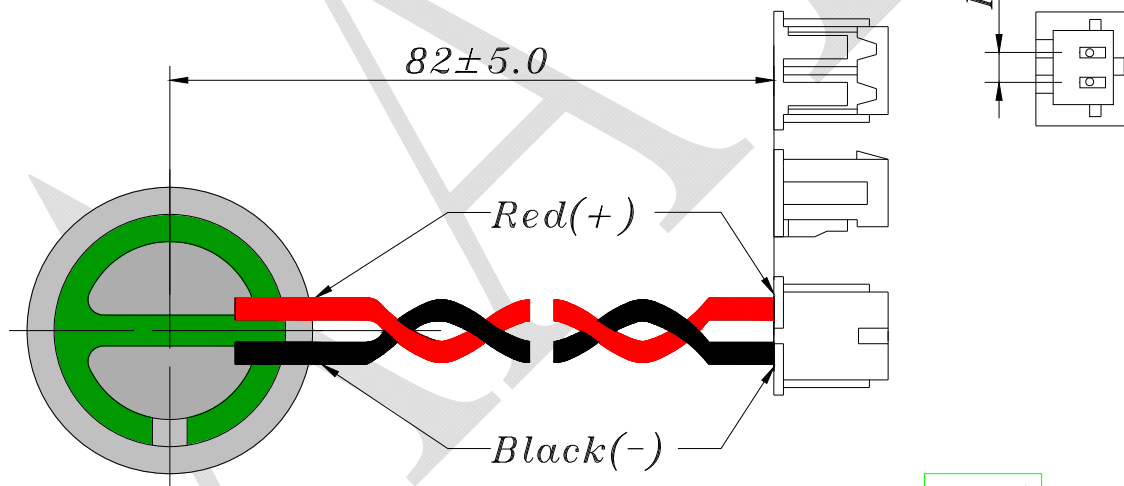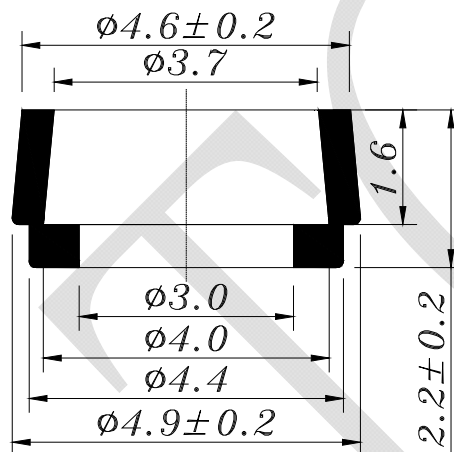

RoHS

TITLE: MICROPHONE

DRAWN: Jack 2013/11/13

SCALE: 5:1 SHEET: 1 of 1

PART NO. AMB-040J38-CWH-IP67

DESIGNED: R & D OF AAT

UNITS: mm

DWG NO. B4015AL-SFN-D80-M

3

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: *****

ONE PLACE DECIMAL ± ***
TWO PLACE DECIMAL ± ***
THREE PLACE DECIMAL ± ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AMB-O40J38-CWH-IP67](#)