 
 



1. SPECIFICATION

AZ-3828S-C

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	
02	Operating Voltage	V	3 ~ 24	
03	Consumption Current	mA (Max)	10	Rated Voltage
04	Resonant Frequency	Hz	2800± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	80	Distance at 30cm Rated Voltage / Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

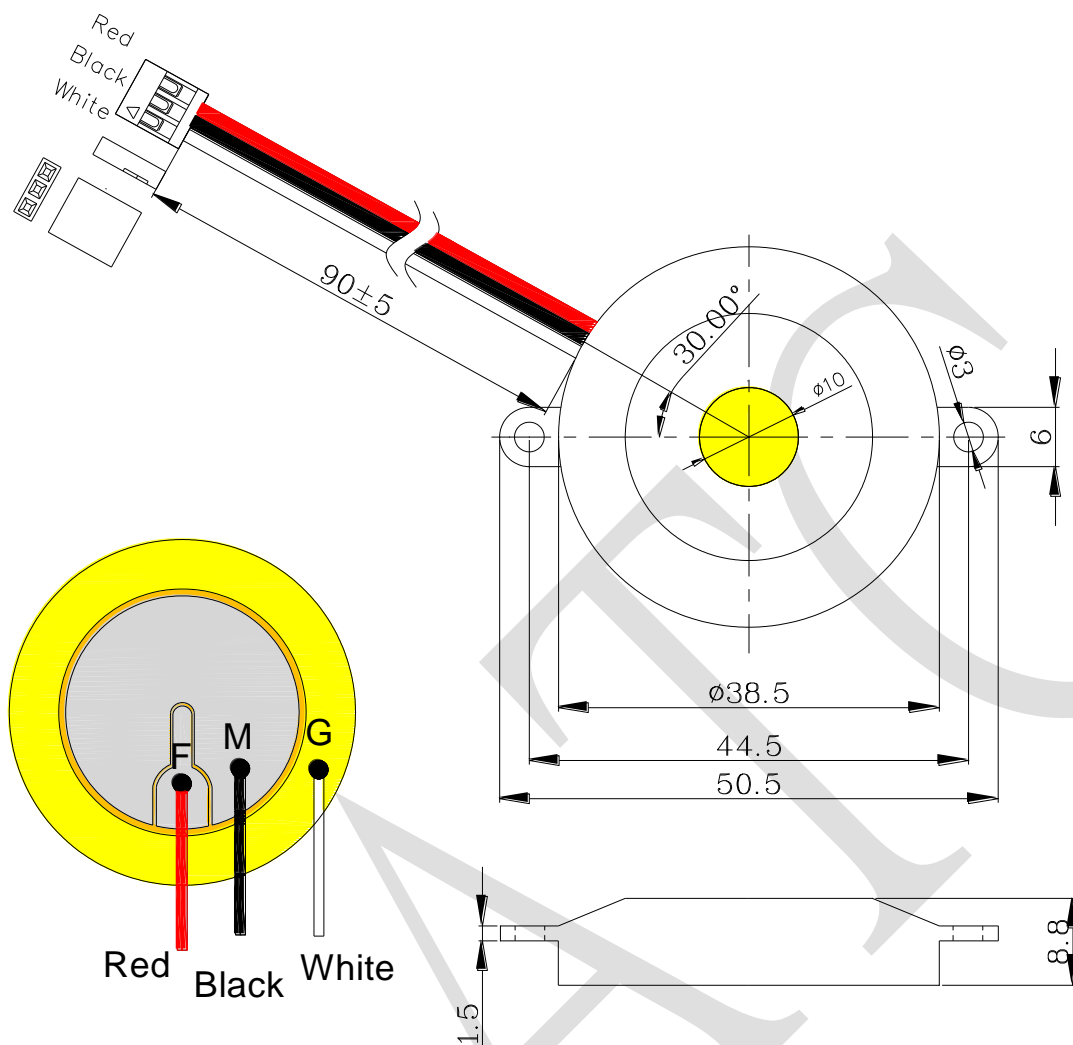

CONNECTOR: A2002H00-3P
WIRE: UL1571, AWG28#

RoHS

TITLE:	PIEZO BUZZER	DRAWN:	Zack	2018/10/24	SCALE: 2:1	SHEET: 1 of 1
PART NO.	AZ-3828S-C	DESIGNED:	R & D OF AAT		UNITS:	mm
DWG NO.	DPE-1075	CHECKED:			TOLERANCE ± 0.5	
		APPROVAL:			UNLESS OTHERWISE SPECIFIED:	
		MATERIAL:	ABS777		ONE PLACE DECIMAL ± ***	
					TWO PLACE DECIMAL ± ***	
					THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-3828S-C](#)