 



1. SPECIFICATION

AC-1203D-RP1 (RoHS)

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 5	
03	Consumption Current	mA (Max)	Mean : 30	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 90	
04	Direct Current Resistance	Ω	45 ± 5	
05	Sound Output (Distance at 10cm)	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2731	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

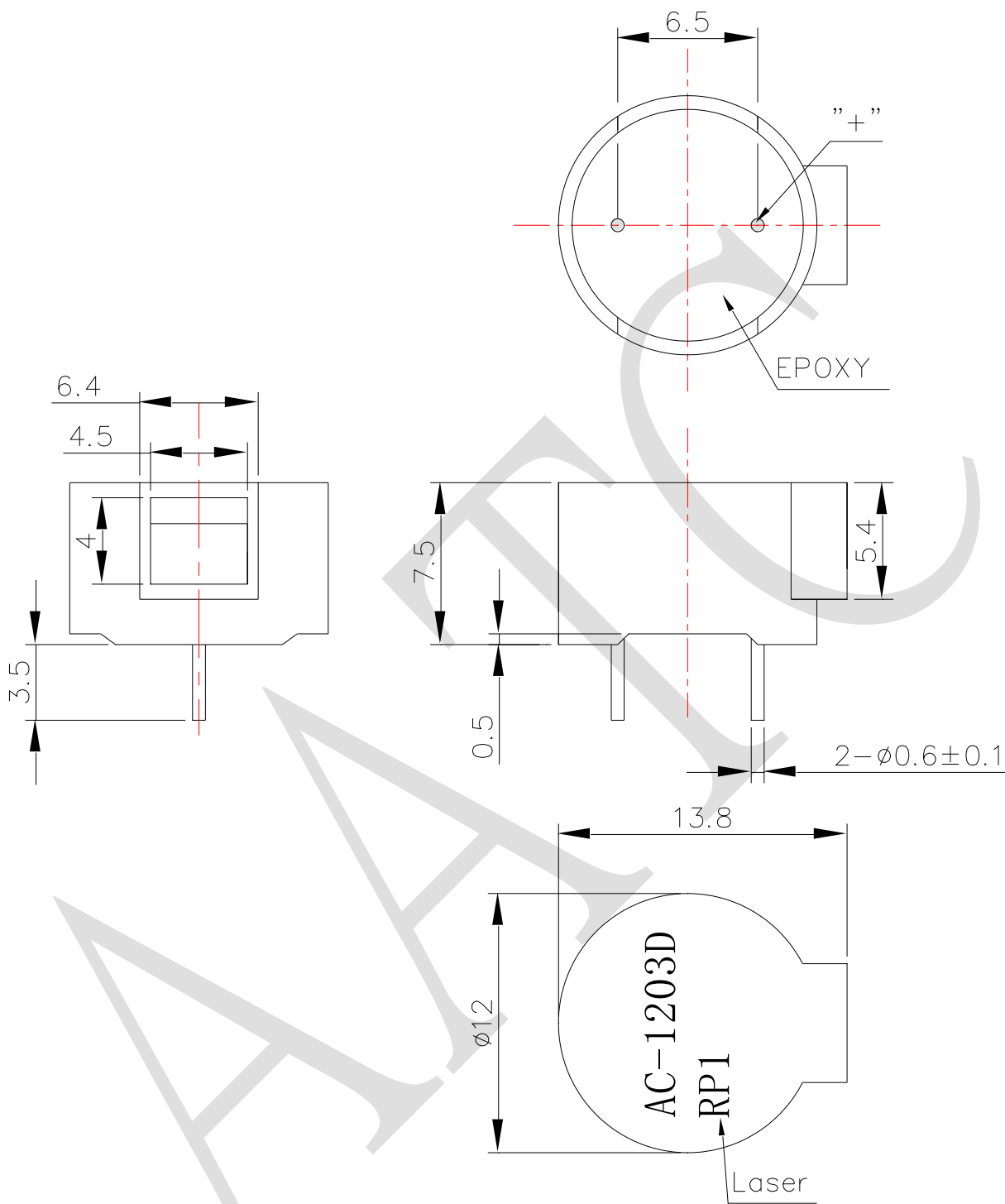

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Zadk	2012/05/02	SCALE: 4:1	SHEET: 1 of 1
PART NO. AC-1203D-RP1	1	DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. ***-*****		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: *****		ONE PLACE DECIMAL ± ***	
				TWO PLACE DECIMAL ± ***	
				THREE PLACE DECIMAL ± ***	



苙翔科技股份有限公司
ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1203D-RP1](#)