


1. SPECIFICATION

AZ-2835S-W-LF (RoHS)

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	4~ 14	
03	Rated Current	mA(Max)	15	Rated Voltage
04	Sound Output (Distance at 30cm )	dBA(Min)	85	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3500	Rated Voltage
06	Resonant Frequency	Hz	3500± 500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

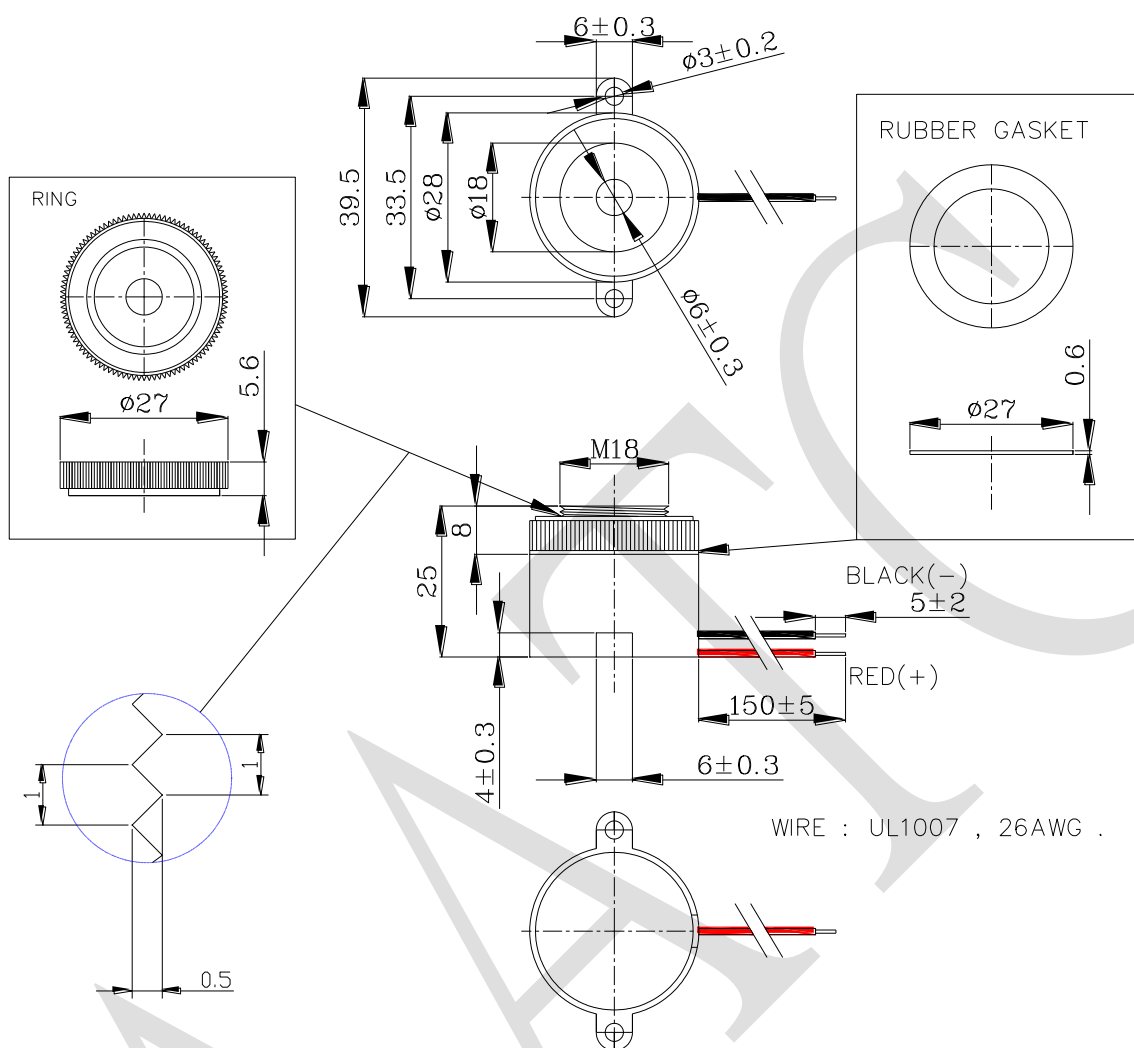

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <i>Zack</i> 2015/03/26	SCALE: 1:1	SHEET: 1 of 1
PART NO. <i>AZ-2835S-W-LF</i>	3	DESIGNED: <i>AATC R&amp;D</i>	UNITS: <i>mm</i>	
DWG NO. <i>UGPA28AX3512W</i>		CHECKED:	TOLERANCE $\pm 0.5$	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL $\pm$ *** TWO PLACE DECIMAL $\pm$ *** THREE PLACE DECIMAL $\pm$ ***	
	REV	MATERIAL: <i>ABS</i>		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-2835S-W-LF