

1. SPECIFICATIONS

AMF-O60C25-1CB

01	Electret's Type	Foil type
02	Sensitivity	-25±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	20- 10 K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥58dB
11	Sound Pressure Level	110 dB

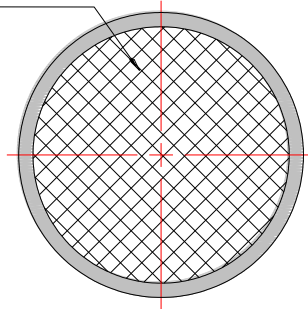
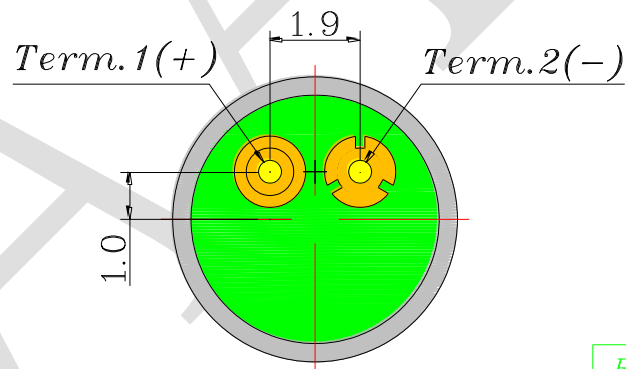
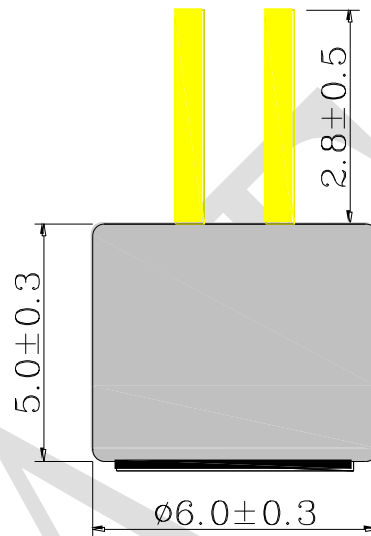
REV NO.

REVISION NOTE

APPROVAL

DATE

FILTER

2- $\phi 0.4 \pm 0.1$ 

RoHS

TITLE: MICROPHONE

DRAWN: *Moose* 2017/07/13

SCALE: 5:1 SHEET: 1 of 1

PART NO. AMF-060C25-1CB

1

DESIGNED: R & D OF AAT

UNITS: mm

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

DWG NO. F6050AP-STN 1180

REV

MATERIAL: AL

ONE PLACE DECIMAL $\pm$ ***TWO PLACE DECIMAL $\pm$ ***THREE PLACE DECIMAL $\pm$ ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AMF-O60C25-1CB](#)