


1.SPECIFICATION DATA

AV-9004-CX2W (RoHS)

Items		Units	Specifications	Conditions
01	Rated Voltage	Vo-p	3.6	
02	Operating Voltage	Vo-p	3.0 ~ 4.0	
03	Consumption Current	mA (max)	Mean 100	Standard State, Standard Drive Circuit. Rated Voltage,Rated Frequency ,Distance at 10 cm free air,Square Wave 1 / 2 Duty
			Peak 300	
04	Sound Output	dB (min)	85	
05	Resonant Frequency	Hz	2731	
06	Coil Resistance	Ω	15 ± 3	At Basic State

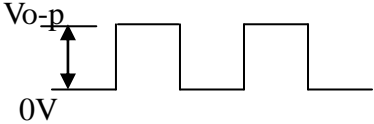

Connector: 杜邦 2.0mm 2P

 $R o H S$

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Jason	2009/05/25	SCALE: 4:1	SHEET: 1 OF 1
PART NO. AV-9004-CX2W		1	DESIGNED: R&D OF AAT	UNITS: mm	
			CHECKED:	TOLERANCE ± 0.3	
DWG NO. HS-09052501		REV	APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
			MATERIAL: LCP	ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AV-9004-CX2W](#)