



1. SPECIFICATION

AX-1212-H2-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	8 ~ 16	
03	Consumption Current	mA (Max)	Mean : 35	Rated Voltage
			Peak : 105	
04	Sound Output	dBA (Min)	83	Distance at 10cm
05	Resonant Frequency	Hz	2300 ± 300	

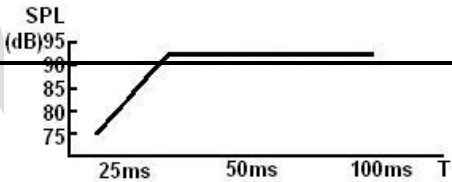

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

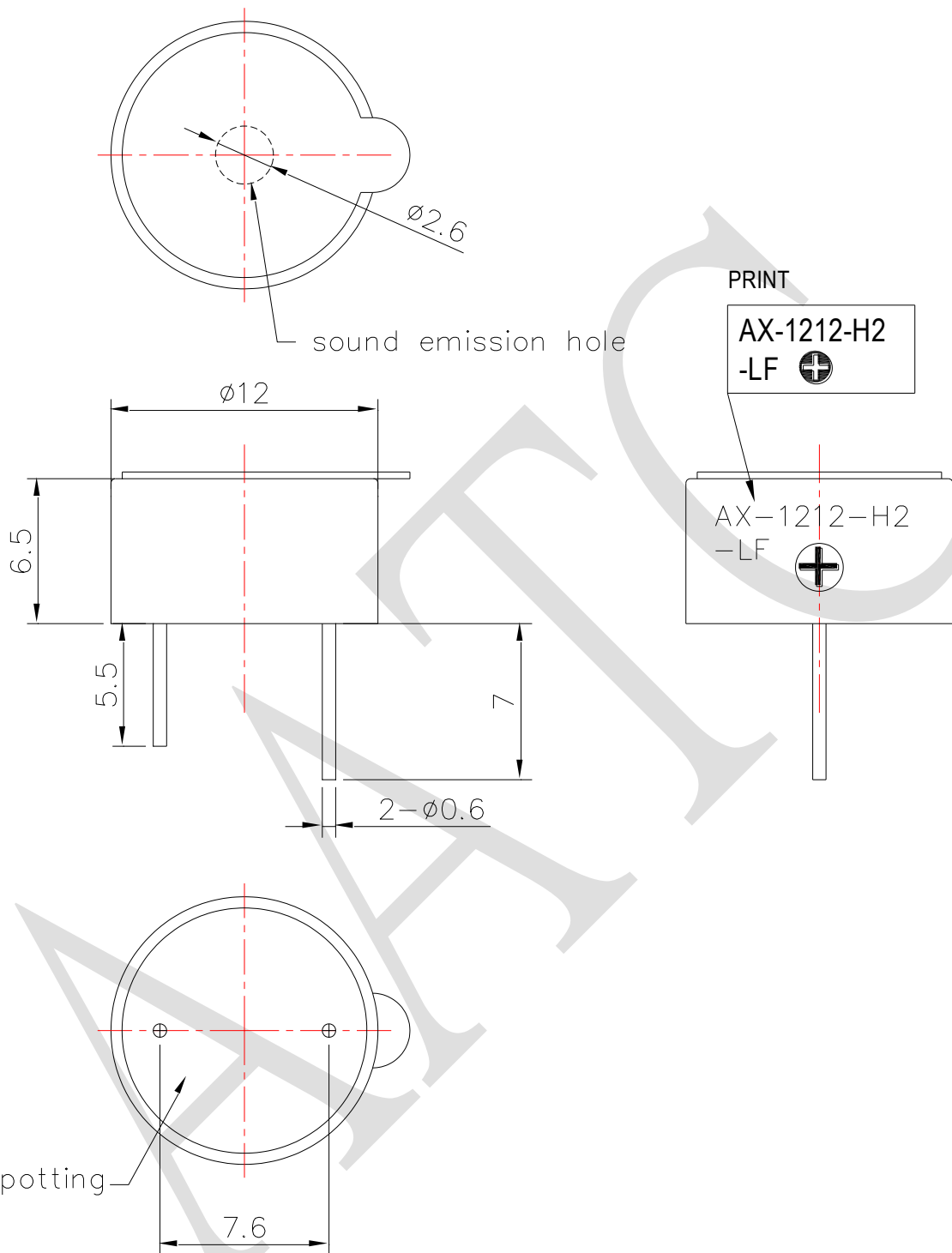

RoHS

TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Zack	2012/06/04	SCALE: 4:1	SHEET: 1 of 1
PART NO. AX-1212-H2-LF		DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. UGCM1212GXP7.0/5.5		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***		
REV		MATERIAL: NORYL			



苙翔科技股份有限公司
 ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1212-H2-LF](#)