

1. SPECIFICATION

AZ-2434S-P-LF (RoHS)


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3~ 20	
03	Rated Current	mA(Max)	15	Rated Voltage
04	Sound Output (Distance at 10cm)	dB(A)(Min)	85	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	3400	
06	Resonant Frequency	Hz	3400± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

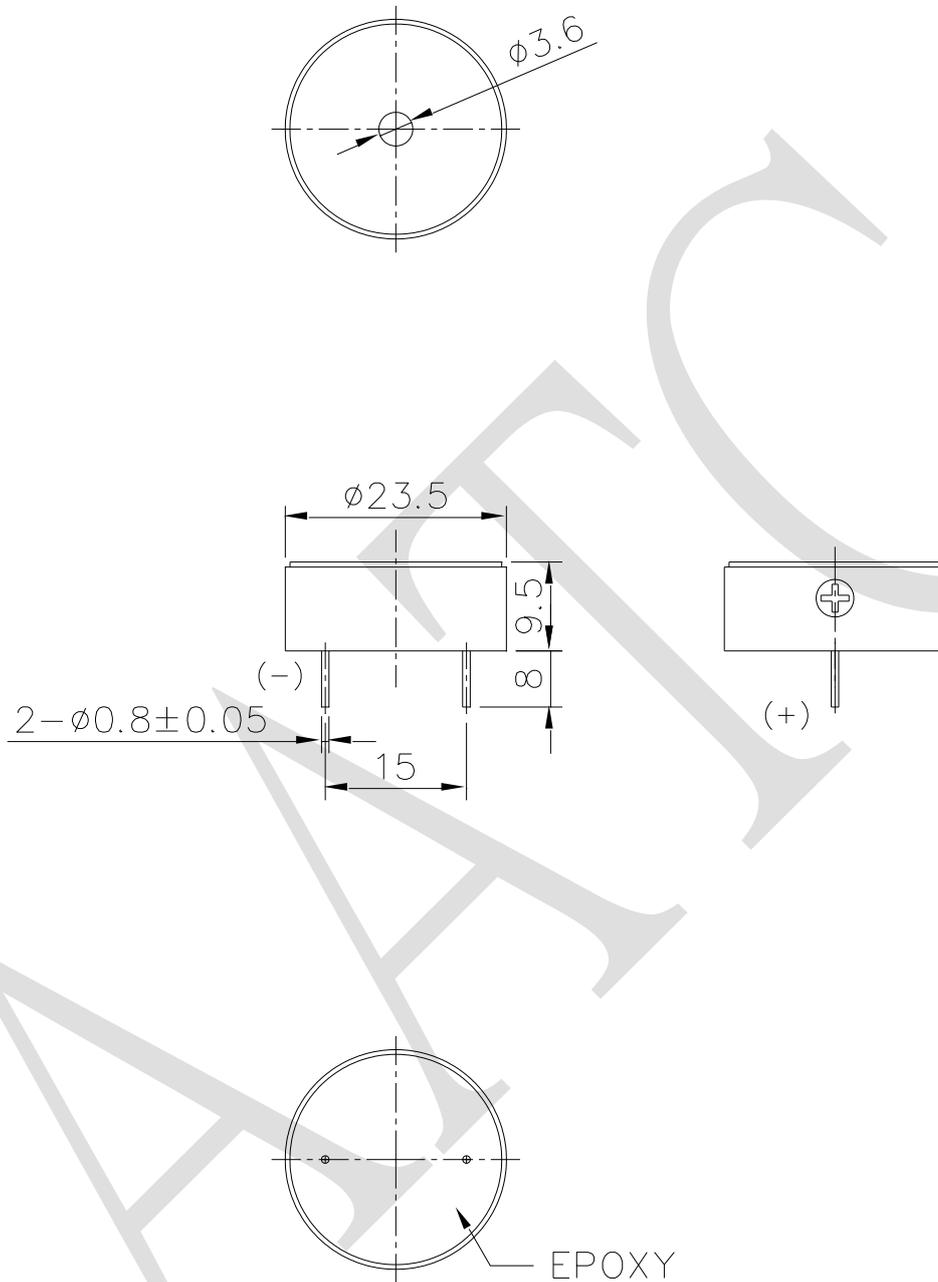

TITLE: PIEZO BUZZER

DRAWN: Zack 2012/10/14

SCALE: 1:1 SHEET: 1 : 1

PART NO. AZ-2434S-P-LF

DESIGNED: R & D OF AAT

UNITS: mm

DWG NO. KPE-228

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL \pm ***

TWO PLACE DECIMAL \pm ***

THREE PLACE DECIMAL \pm ***

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-2434S-P-LF](#)