 
 



1. SPECIFICATION

AZ-2333S-2C2



ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	8 ~ 15	
03	Consumption Current	mA (Max)	20	Rated Voltage
04	Resonant Frequency	Hz	3300 ± 500	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	90	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

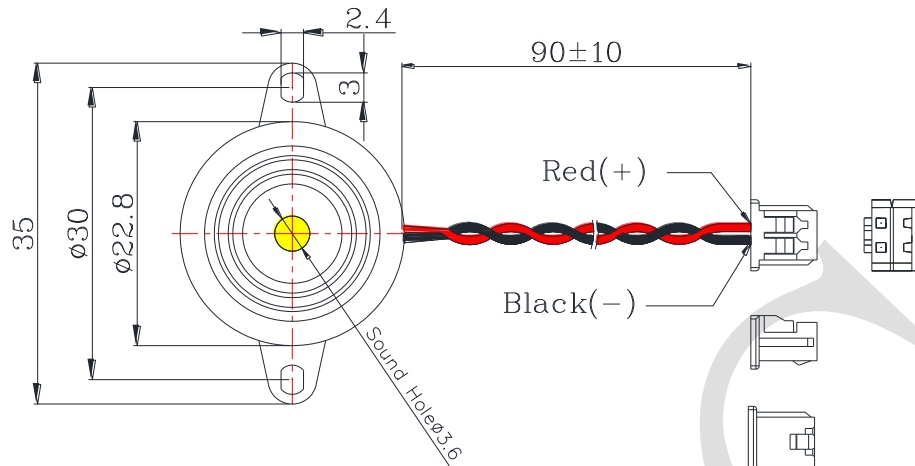

Laser

AZ-2333S-2C2

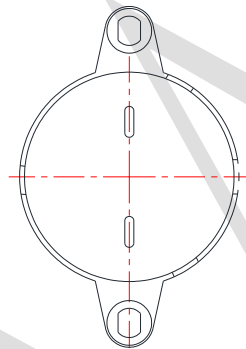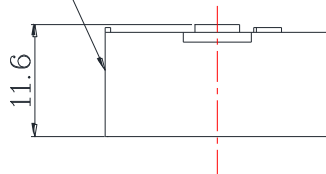

Wire: UL1571,AWG28#
Connector: Equivalent to Molex
51021-0200

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zak	2019/12/13	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-2333S-2C2</i>	2	DESIGNED: <i>R & D OF AAT</i>		UNITS: <i>mm</i>	
DWG NO. <i>BPC2312JWC90-1233</i>		CHECKED:		TOLERANCE ± 0.5	
	REV	APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: <i>PBT</i>		ONE PLACE DECIMAL \pm ***	
				TWO PLACE DECIMAL \pm ***	
				THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AZ-2333S-2C2](#)