


1. SPECIFICATION

AZ-3511E-2C


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	10	 Square wave 1/2 duty.
02	Operating Voltage	V	1~ 30	
03	Consumption Current	mA (Max)	9	
04	Sound pressure level (Distance at 10cm)	dB(A) (Min)	80	Rated voltage, rated frequency.
05	Capacitance	pF	50000±30%	At 1KHz
06	Rated Frequency	Hz	1100± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

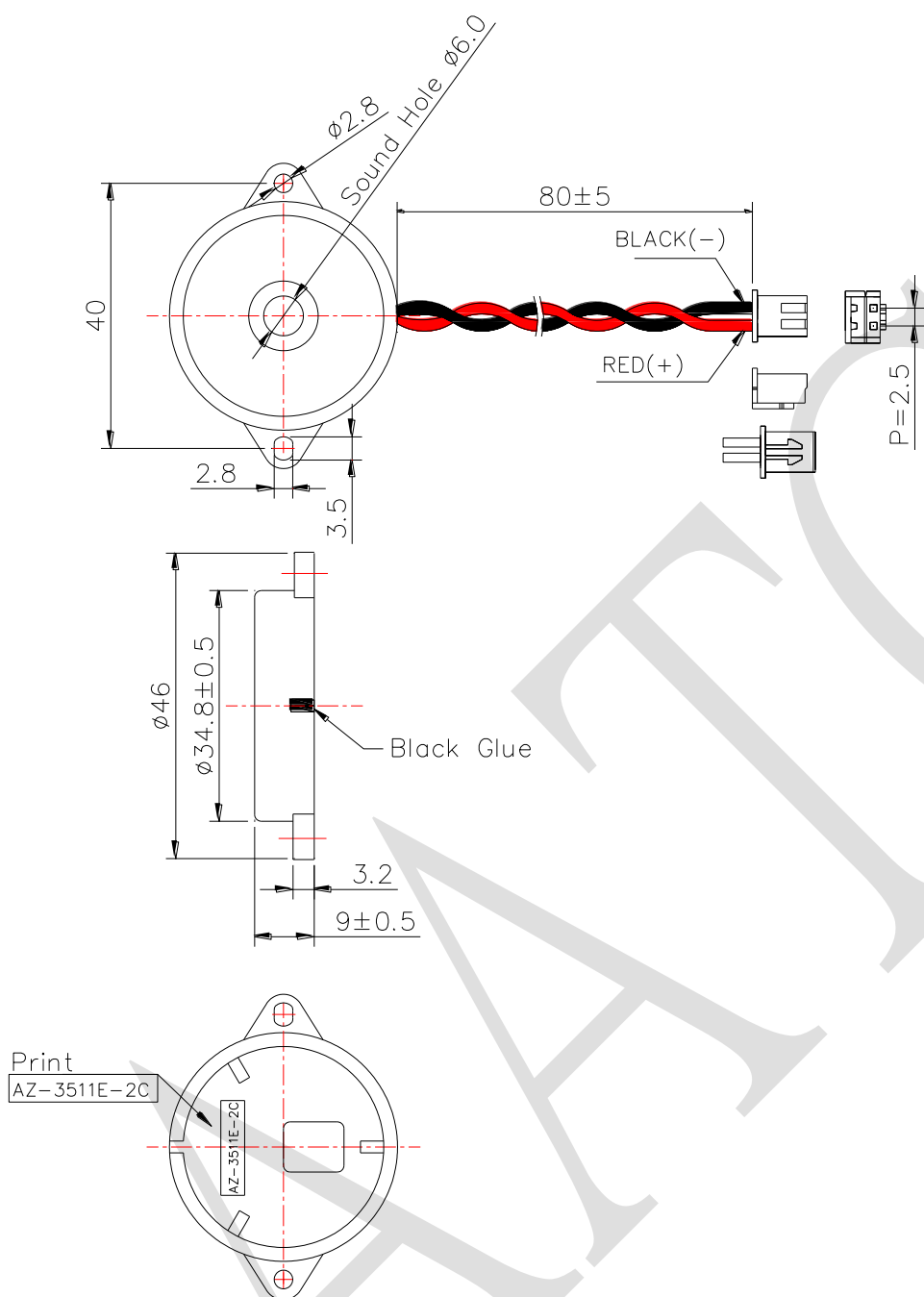

WIRE: UL1007, AWG28#

Connector: Equivalent to JST XHP-02

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Zack	2017/07/25	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-3511E-2C</i>	2	DESIGNED: <i>R&D OF AAT</i>	UNITS: <i>mm</i>		
DWG NO. <i>BP3590W80C-11</i>		CHECKED:	TOLERANCE ± 0.5		
REV		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
		MATERIAL: <i>ABS</i>	ONE PLACE DECIMAL \pm ***		
			TWO PLACE DECIMAL \pm ***		
			THREE PLACE DECIMAL \pm ***		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AZ-3511E-2C](#)