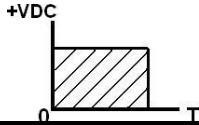
 


1. SPECIFICATION

AX-1005-2P


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	
02	Operating Voltage	V	4 ~ 7	
03	Consumption Current	mA (Max)	30	Rated Voltage
04	Resonant Frequency	Hz	2730± 300	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	80	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.

REVISION NOTE

APPROVAL

DATE

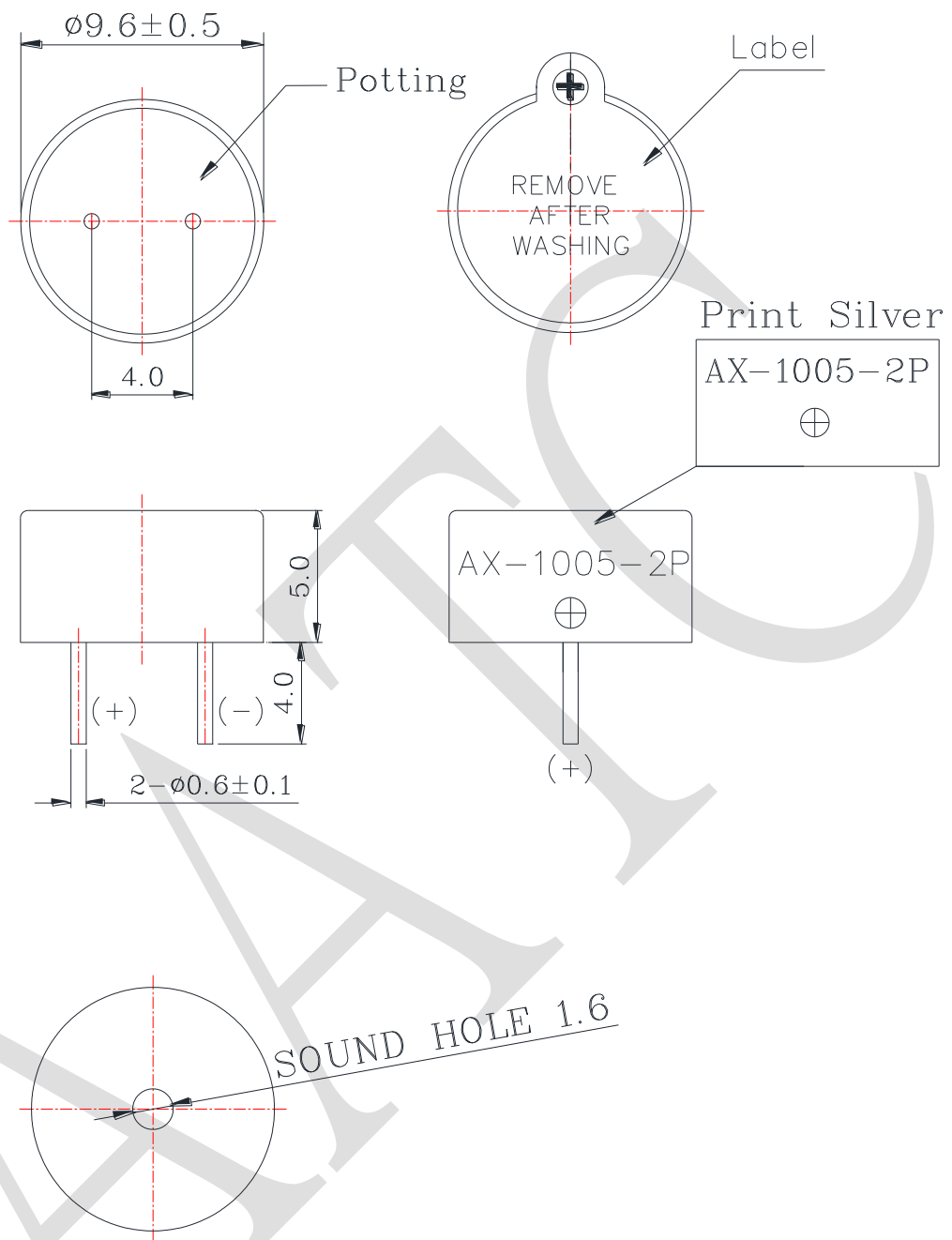

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Hank 2020-04-10

SCALE: 4:1 SHEET: 1 of 1

PART NO. AX-1005-2P

DESIGNED: R&D OF AAT

UNITS: mm

5

CHECKED:

TOLERANCE ± 0.5

DWG NO.

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

FDM-3386 FDB-096050F-05027-1

REV

MATERIAL: PPA

ONE PLACE DECIMAL \pm ***TWO PLACE DECIMAL \pm ***THREE PLACE DECIMAL \pm ***

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AX-1005-2P](#)