 



1. SPECIFICATION


AC-1405G-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5.0	
02	Operating Voltage	V	4.0 ~ 6.0	
03	Consumption Current	mA Max.	50	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	85	Standard state, standard drive circuit. Square wave 1/2 duty.
05	Direct Current Resistance	Ω	40±6	Rated voltage, rated frequency.
06	Rated Frequency	Hz	2000	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

PRINT

測印銀：AC-1405G-LF

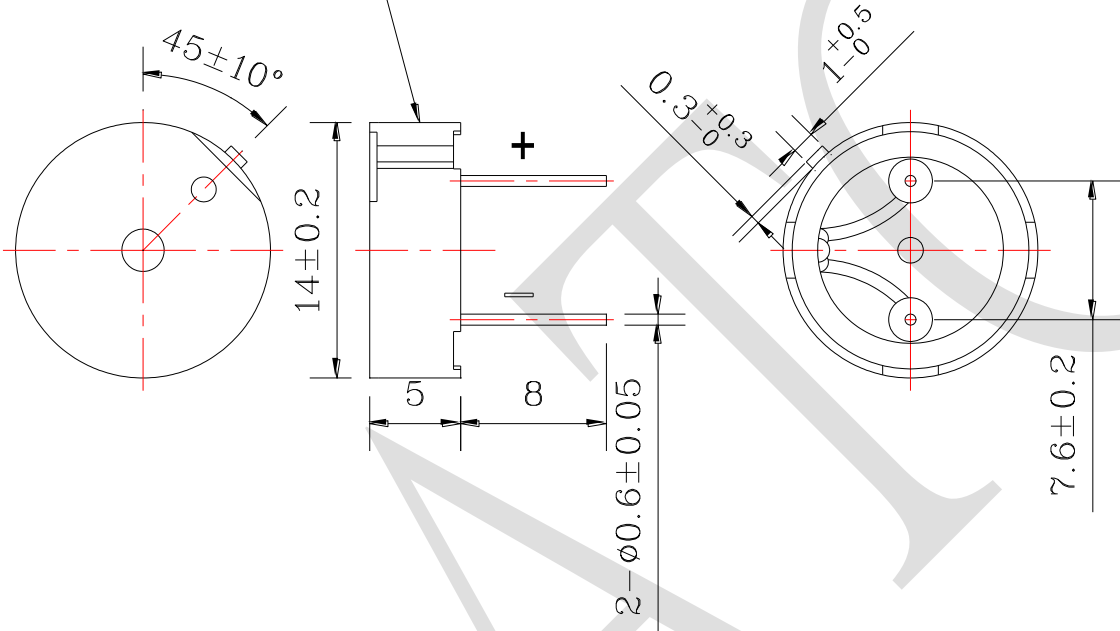


RoHS

TITLE: SOUND TRANSDUCER DIMENSIONS		DRAWN: Moose	2018-08-07	SCALE: 3/1	SHEET: 1 OF 1
PART NO. AC-1405G-LF	2	DESIGNED: R&D OF AAT	UNITS: mm		
DWG NO. UGFP-05A		CHECKED:	TOLERANCE ± 0.5		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL ± *** TWO PLACE DECIMAL ± *** THREE PLACE DECIMAL ± ***		
	REV	MATERIAL: NORYL			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1405G-LF](#)