

1. SPECIFICATION

AZ-4228S-C5


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	1.5 ~ 20	
03	Rated Current	mA(Max)	9	Rated Voltage
04	Sound pressure level (Distance at 30cm )	dBA(Min)	96	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	2800	Rated Voltage
06	Resonant Frequency	Hz	2800 ± 500	

REV NO.

REVISION NOTE

APPROVAL

DATE

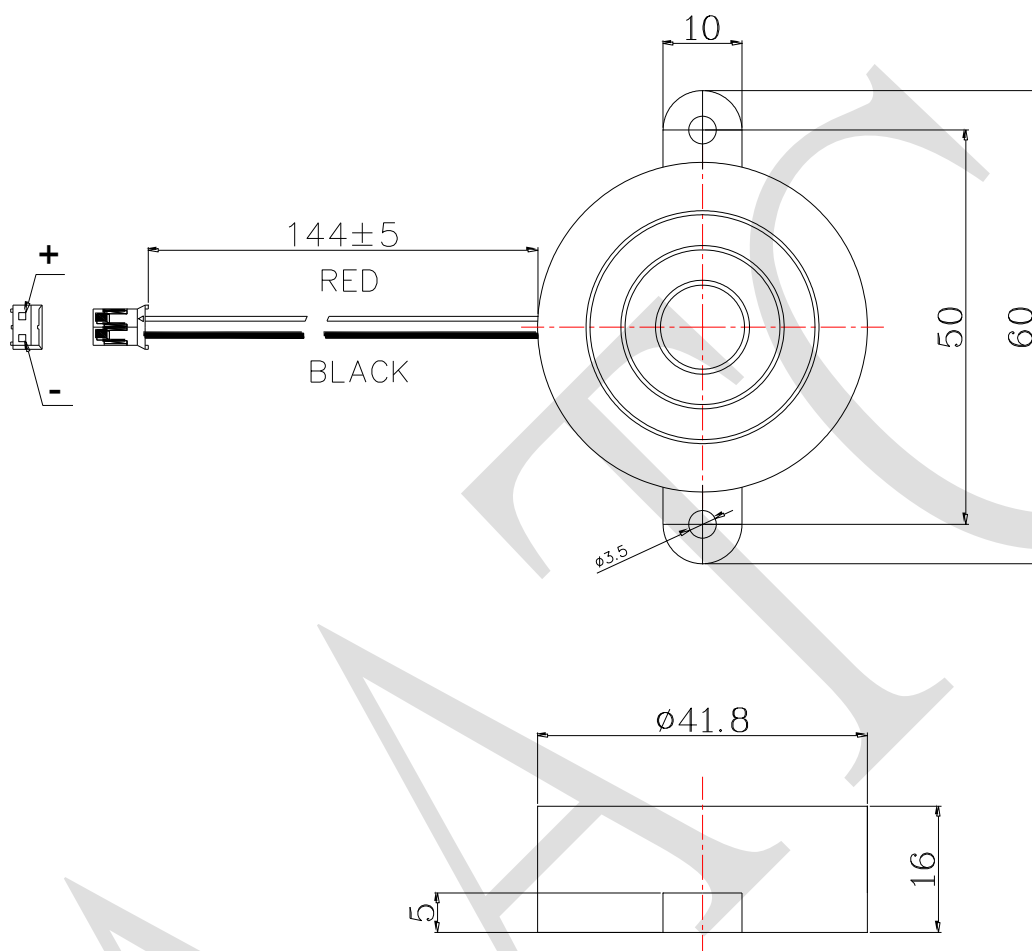

WIRE: UL1007, AWG24.

CONNECTOR: JST PHR-2 COMPATIBLE.

HOUSING JST PH 2.0, 2PIN.

RoHS

TITLE: PIEZO BUZZER

DRAWN: Zack

2013/12/05

SCALE: 2:1 SHEET: 1 of 1

PART NO. AZ-4228S-C5

DESIGNED: R &amp; D OF AAT

UNITS: mm

DWG NO. UGPA42CX2812WC144

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± \*\*\*

TWO PLACE DECIMAL ± \*\*\*

THREE PLACE DECIMAL ± \*\*\*

MATERIAL: ABS



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AZ-4228S-C5