

1. SPECIFICATIONS

AMF-O97A36-CWH1


01	Electret's Type	Foil type
02	Sensitivity	-36±3dB (0dB=1V/Pa,1KHz)
03	Standard Operation Voltage	2.0 V
04	Output Impedance	2.2 KΩ
05	Directivity	Omni directional
06	Frequency Range	100 - 20K Hz
07	Max. Operation Voltage	10V
08	Current Consumption	Max.0.5mA
09	Sensitivity Reduction	Within -3dB 0dB=1V/Pa,1KHz Vs=2.0to 1.5V
10	S/N Ratio	≥58dB
11	Sound Pressure Level	110 dB

REV NO.

REVISION NOTE

APPROVAL

DATE

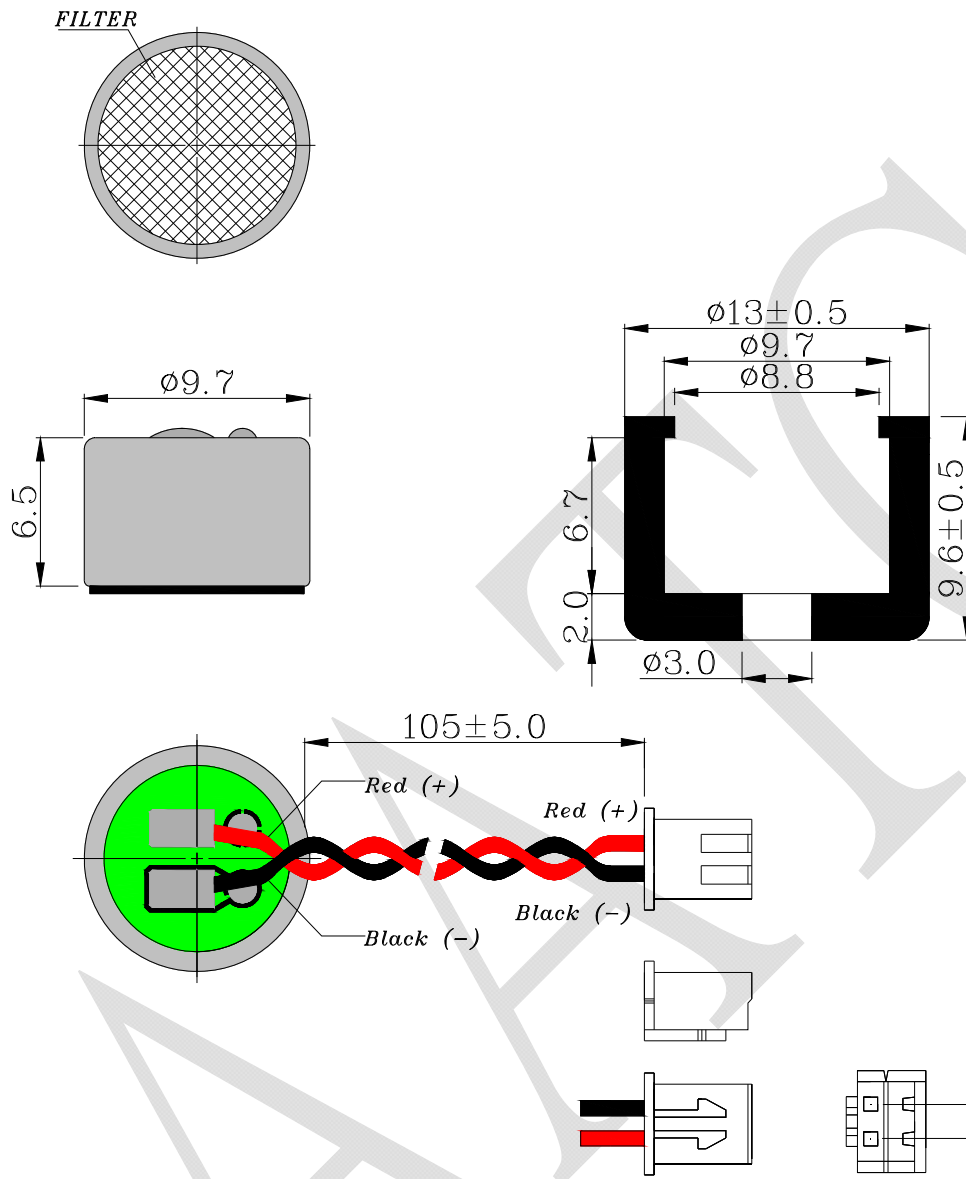

Wire: UL1061,26#AWG;
 Connector: Equivalent to JST XHP-2
 Holder: DD-EQ-JTE13-04

RoHS

TITLE: MICROPHONE		DRAWN: Zack	2014/10/03	SCALE: 5:1	SHEET: 1 of 1
PART NO. AMF-097A36-CWH1	2	DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. F9765AL-SN-D110-M 7775		CHECKED:		TOLERANCE ± 0.3	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: *****		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AMF-O97A36-CWH1](#)