 


1. SPECIFICATION

AS-1201B-LF

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	
02	Operating Voltage	V	1.0 ~ 2.0	
03	Consumption Current	mA (Max)	Mean : 20	Standard state, standard drive circuit. Rated voltage, rated frequency, Square wave 1/2 duty.
			Peak : 60	
04	Sound pressure level (Distance at 10cm)	dB(A) (Min)	85	
05	Direct Current Resistance	Ω	42±6.3	
06	Rated Frequency	Hz	2048	

REV NO.




REVISION NOTE

APPROVAL

DATE

Print

AS-1201B-LF ⊕

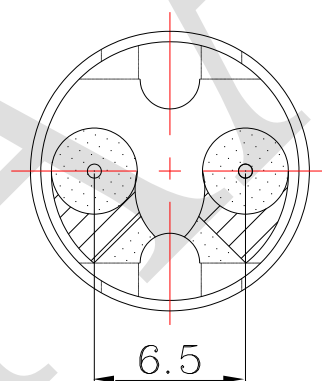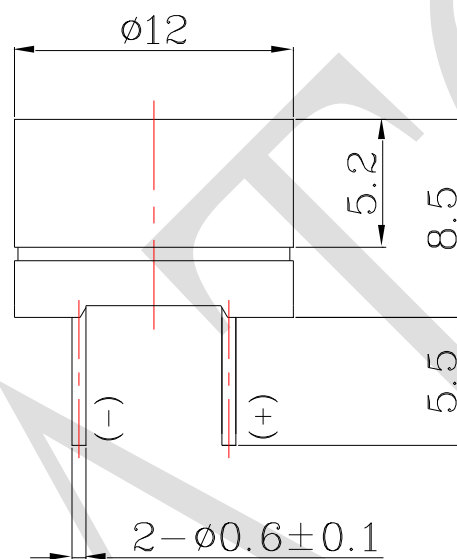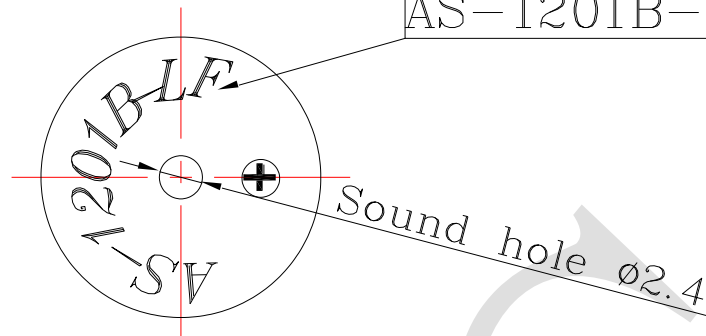

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Jerry 2013/03/12

SCALE: 4:1 SHEET: 1 of 1

PART NO. AS-1201B-LF

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGC12G-2P5.5A

2

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: NORYL

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AS-1201B-LF](#)