
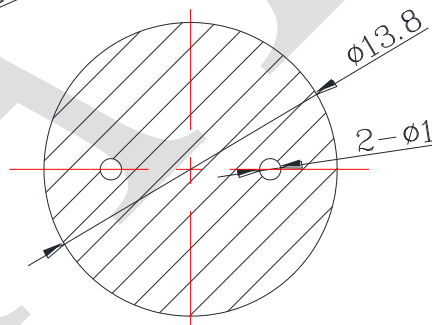
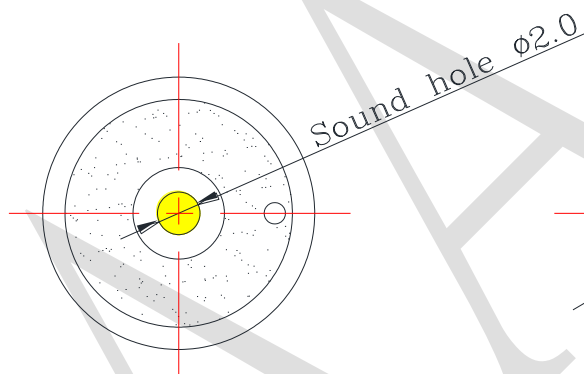
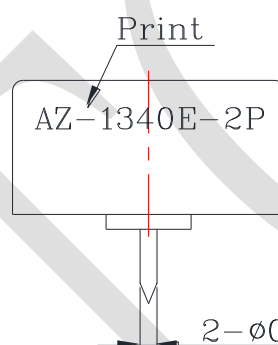
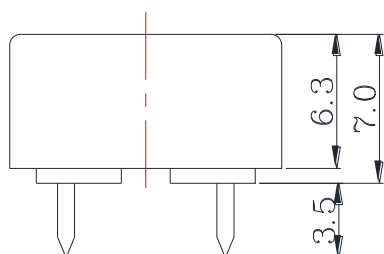
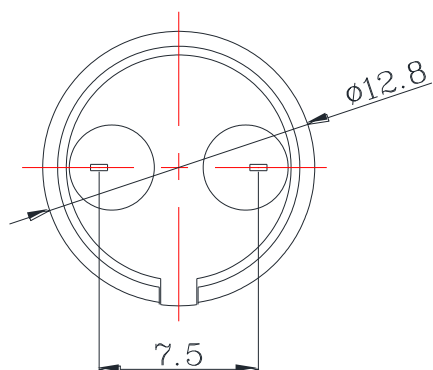


## 1. SPECIFICATION

AZ-1340E-2P

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	5	 Square wave 1/2 duty.
02	Operating Voltage	V	1 ~ 30	
03	Consumption Current	mA (Max)	2	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	75	Rated voltage, rated frequency.
05	Capacitance	pF	11000±30%	At 1000Hz
06	Rated Frequency	Hz	4000± 500	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RECOMMENDED PCB LAYOUT

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: <b>Zak</b>	2019/11/15	SCALE: 2:1	SHEET: 1:1
PART NO. <i>AZ-1340E-2P</i>	2	DESIGNED: <i>R&amp;D OF AAT</i>	UNITS: <i>mm</i>		
DWG NO. <i>AT1340TP</i>		CHECKED:	TOLERANCE $\pm 0.5$		
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:		
	REV	MATERIAL: <i>PBT</i>	ONE PLACE DECIMAL $\pm$ ***		
			TWO PLACE DECIMAL $\pm$ ***		
			THREE PLACE DECIMAL $\pm$ ***		



**ADVANCED ACOUSTIC TECHNOLOGY CORPORATION**

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1340E-2P](#)