
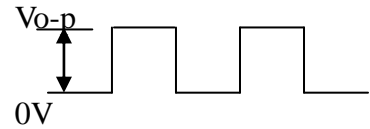


File Name

AP-1205G-F2-LF (RoHS)

Items		Units	Specifications	Conditions
01	Rated Voltage	Vo-p	5	
02	Operating Voltage	Vo-p	3~8	
03	Mean Current	mA (Max)	50	Applying rated voltage, rated frequency Square wave,1/2 duty subject to standard state.
04	Direct Current Resistance	Ohm	40±5	
05	Sound Output	dBa (min)	85	Distance at 10cm,applying rated voltage, rated frequency square wave, 1/2duty subject to standard state.
06	Rated Frequency	Hz	2400	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

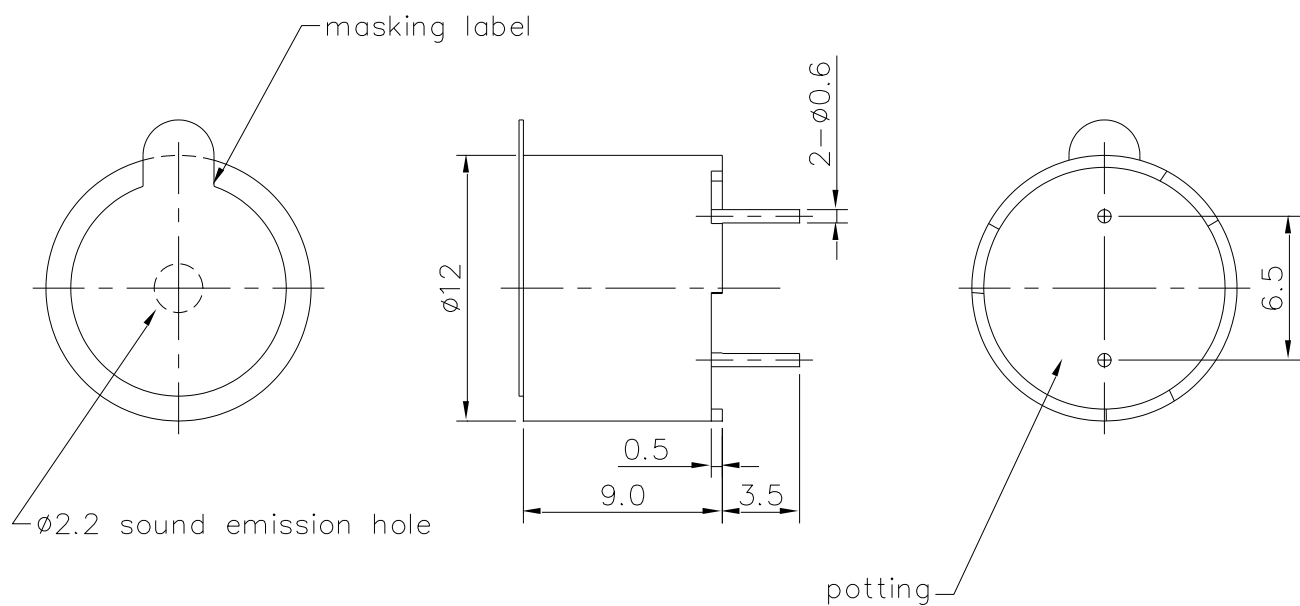

TITLE: <i>SOUND TRANSDUCER</i>		DRAWN: <b>JOHN</b> 05/26/2003	SCALE: 3:1	SHEET: 1 of 1
PART NO. <i>AP-1205G-F2-LF</i>	1	DESIGNED: <i>R&amp;D OF AAT</i>	UNITS: <i>mm</i>	
DWG NO. <i>DTE-2052</i>		CHECKED:	TOLERANCE $\pm 0.5$	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL $\pm$ *** TWO PLACE DECIMAL $\pm$ *** THREE PLACE DECIMAL $\pm$ ***	
	REV	MATERIAL: <i>PBT</i>		



苙翔科技股份有限公司  
 ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AP-1205G-F2-LF