 


# 1. SPECIFICATION

AZ-1348E-4WV1




ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	 Square wave 1/2 duty.
02	Operating Voltage	V	1 ~25	
03	Consumption Current	mA (Max)	5	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	80	Rated voltage, rated frequency.
05	Capacitance	pF	10000±30%	At 1KHz
06	Rated Frequency	Hz	4800 ±500	

REV NO.

REVISION NOTE

APPROVAL

DATE

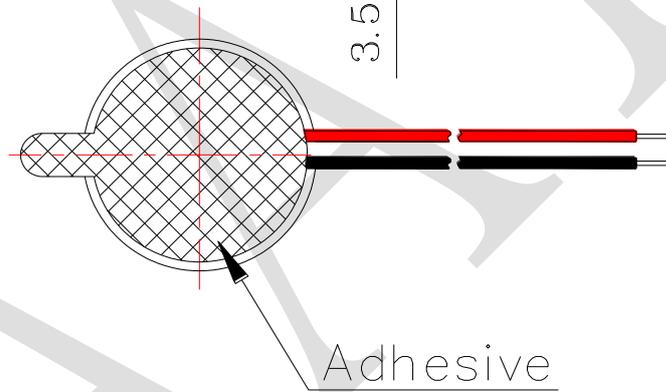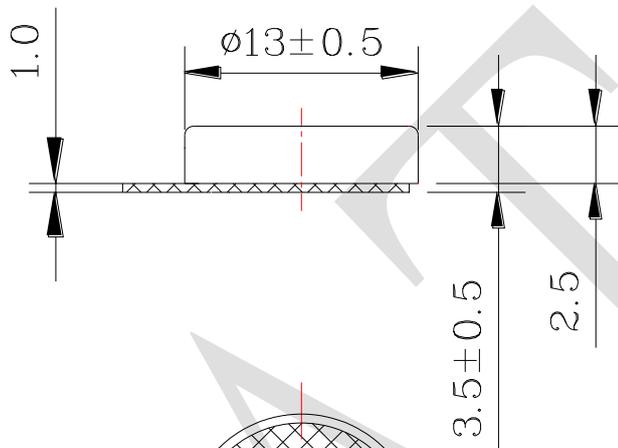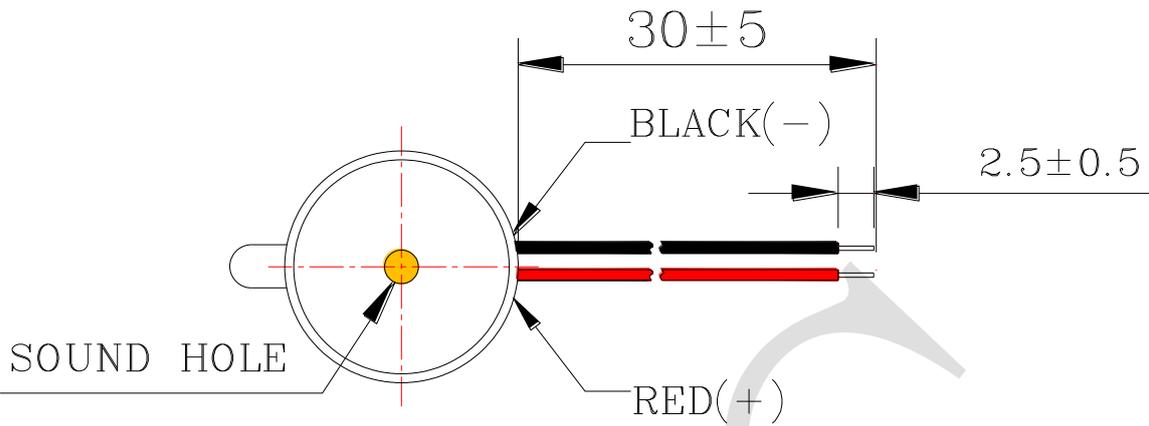

Wire: UL 1571.AWG32#

RoHS

TITLE: <b>PIEZO BUZZER</b>		DRAWN: <b>Zack</b> 2016/08/17		SCALE: 2:1	SHEET: 1:1
PART NO. <b>AZ-1348E-4WV1</b>		DESIGNED: <b>R&amp;D OF AAT</b>		UNITS: <b>mm</b>	
DWG NO. <b>BP1325W30-48(013-132510-24)</b>		CHECKED:		TOLERANCE $\pm 0.3$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
REV <b>1</b>		MATERIAL: <b>ABS</b>		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



**ADVANCED ACOUSTIC TECHNOLOGY CORPORATION**

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1348E-4WV1](#)