 

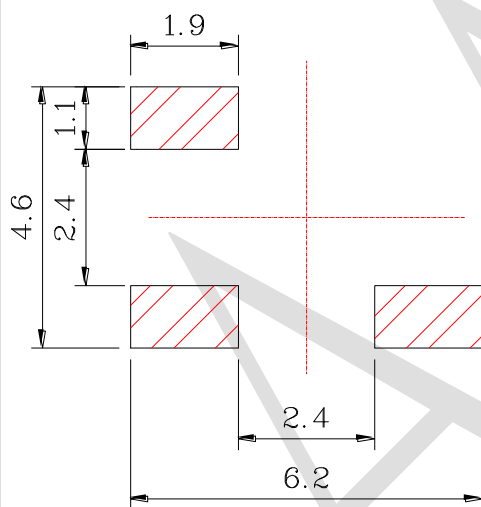


1. SPECIFICATION

AD-5503-PP

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	
02	Operating Voltage	V	2 ~ 4	
03	Consumption Current	mA (Max)	Mean : 110	Standard state, standard drive circuit. Rated voltage, rated frequency, Square wave 1/2 duty.
			Peak : 330	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	70	
05	Direct Current Resistance	Ω	12±3	
06	Rated Frequency	Hz	4000	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

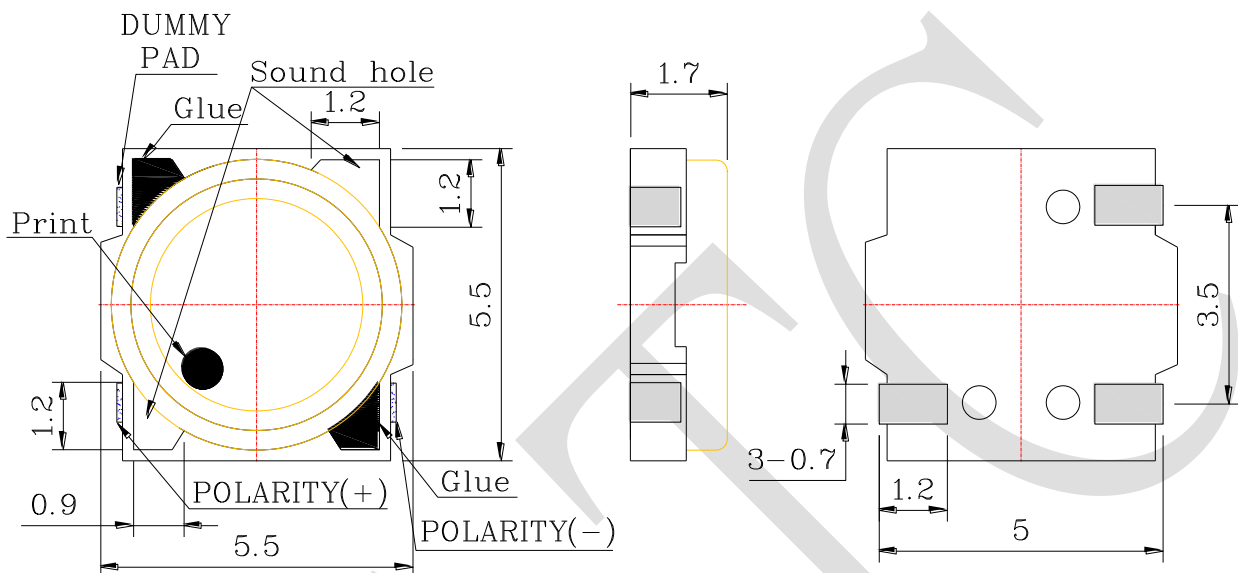

RECOMMENDED PCB LAYOUT

RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: <b>Moose</b>	2015/07/21	SCALE: 1:1	SHEET: 1 : 1
PART NO. AD-5503-PP		DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. FDM-3136 SMD-055017F-03040		CHECKED:		TOLERANCE $\pm 0.5$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: LCP		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

AD-5503-PP