
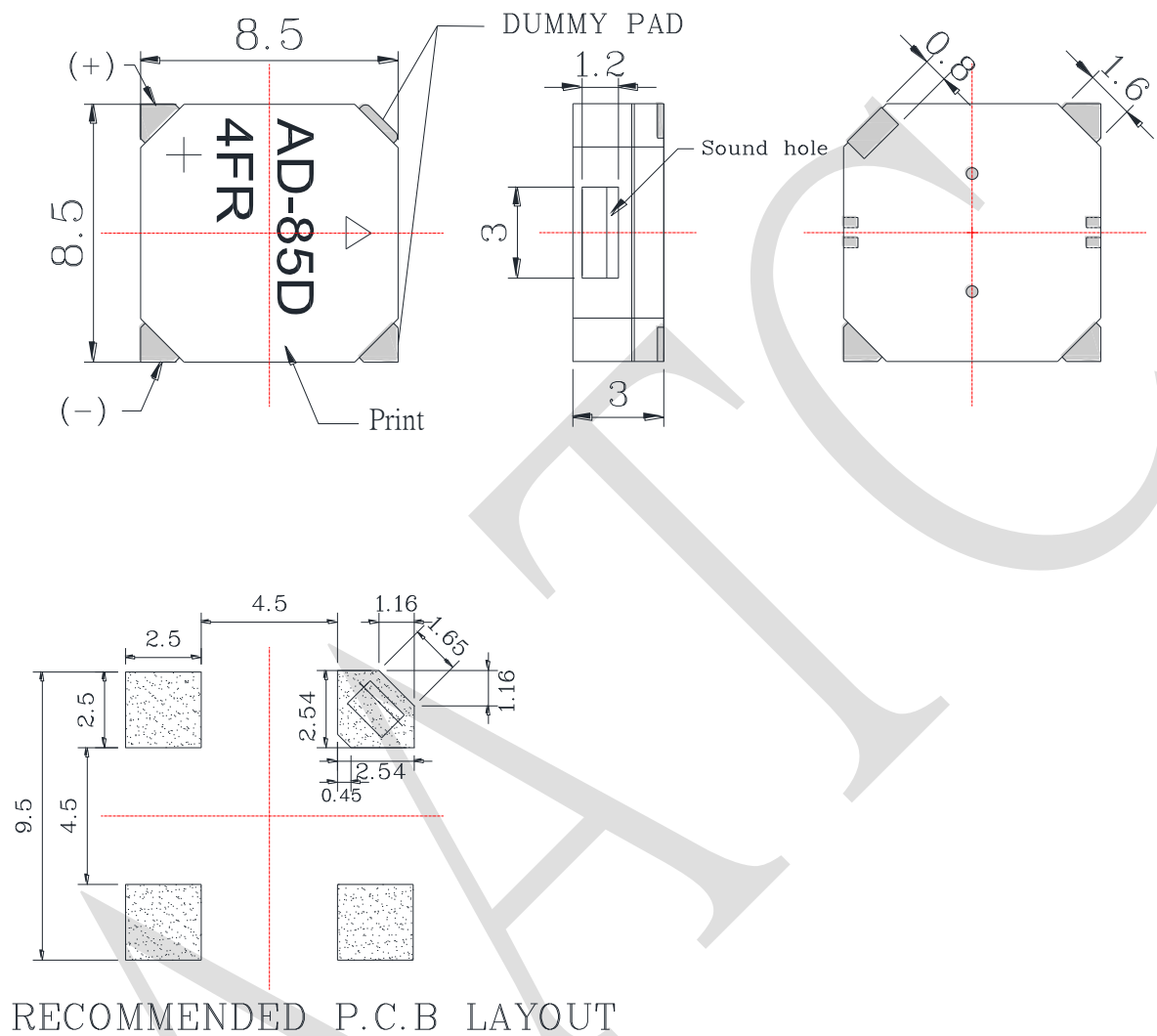


1. SPECIFICATION

AD-85D4FR

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.6	<div><div>V_{p-p}</div><div>0V</div></div> <div>Standard state, standard drive circuit. Square wave 1/2 duty.</div>
02	Operating Voltage	V	2.5 ~ 4.5	
03	Consumption Current	mA Max.	100	
04	Sound pressure level (Distance at 10cm)	dB(A) Min.	90	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	16±3	
06	Rated Frequency	Hz	4000	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Hank	2019/12/24	SCALE: 1:1	SHEET: 1 : 1
PART NO.	AD-85D4FR	5	DESIGNED: R & D OF AAT	UNITS: mm	TOLERANCE ± 0.5 UNLESS OTHERWISE SPECIFIED: ONE PLACE DECIMAL \pm *** TWO PLACE DECIMAL \pm *** THREE PLACE DECIMAL \pm ***
DWG NO.			CHECKED:		
			APPROVAL:		
	REV		MATERIAL: LCP		



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AD-85D4FR](#)