 


1. SPECIFICATION

AP-2509T-P1






ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	
02	Operating Voltage	V	4 ~ 10	
03	Consumption Current	mA (Max)	Mean : 65	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 195	
04	Direct Current Resistance	Ω	65 ± 5	
05	Sound Output (Distance at 10cm)	dBA (Min)	85 (5V)	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			90 (9V)	
06	Rated Frequency	Hz	1000	

REV NO.

REVISION NOTE

APPROVAL

DATE

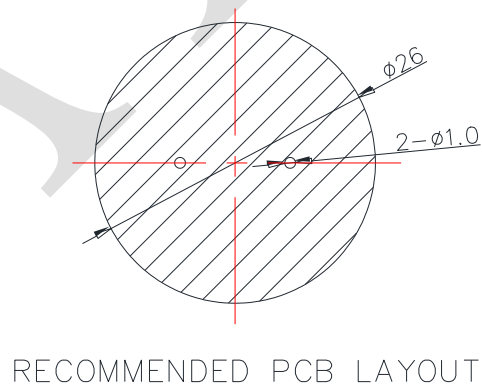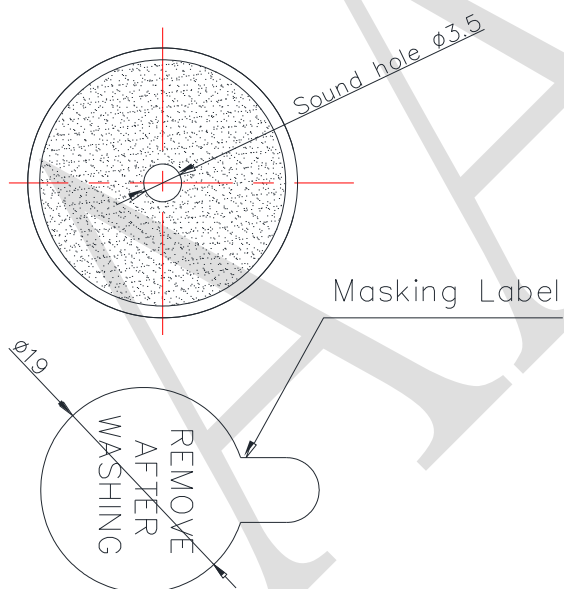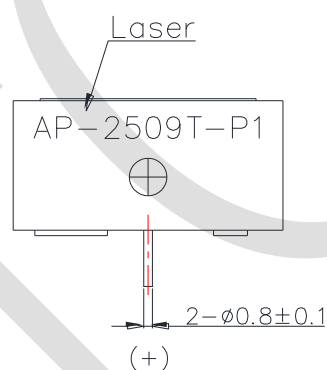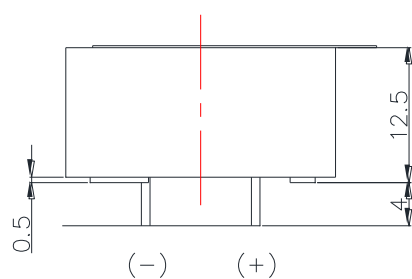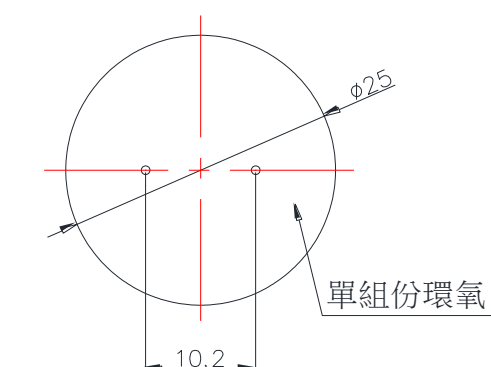

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Moose 2016/01/19 SCALE: 4:1 SHEET: 1 of 1

PART NO. AP-2509T-P1

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGCM2509P4.0T

CHECKED:

TOLERANCE ± 0.5

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

MATERIAL: NORYL

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AP-2509T-P1](#)