


1. SPECIFICATION

AZ-4228S-W19

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	VDC
02	Operating Voltage	V	3~ 20	
03	Rated Current	mA(Max)	20	Rated Voltage
04	Sound pressure level (Distance at 30cm)	dBA(Min)	96	Rated Voltage Rated Frequency
05	Rated Frequency	Hz	2800	Rated Voltage
06	Resonant Frequency	Hz	2800± 200	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

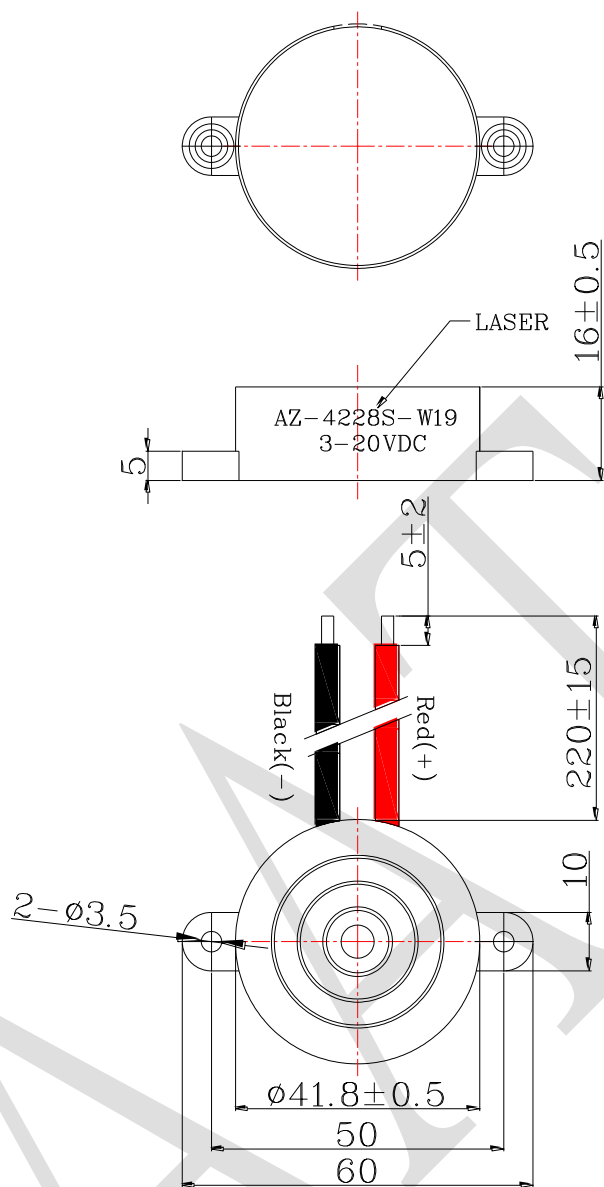

Wire: UL1007, AWG28#

RoHS

TITLE: <i>PIEZO BUZZER</i>		DRAWN: Moose 2018-06-12	SCALE: 2:1	SHEET: 1 of 1
PART NO. <i>AZ-4228S-W19</i>	3	DESIGNED: R & D OF AAT	UNITS: mm	
DWG NO. <i>UGPA42CX2812W220</i>		CHECKED:	TOLERANCE ± 0.5	
		APPROVAL:	UNLESS OTHERWISE SPECIFIED:	
	REV	MATERIAL: ***	ONE PLACE DECIMAL \pm ***	
			TWO PLACE DECIMAL \pm ***	
			THREE PLACE DECIMAL \pm ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AZ-4228S-W19](#)