
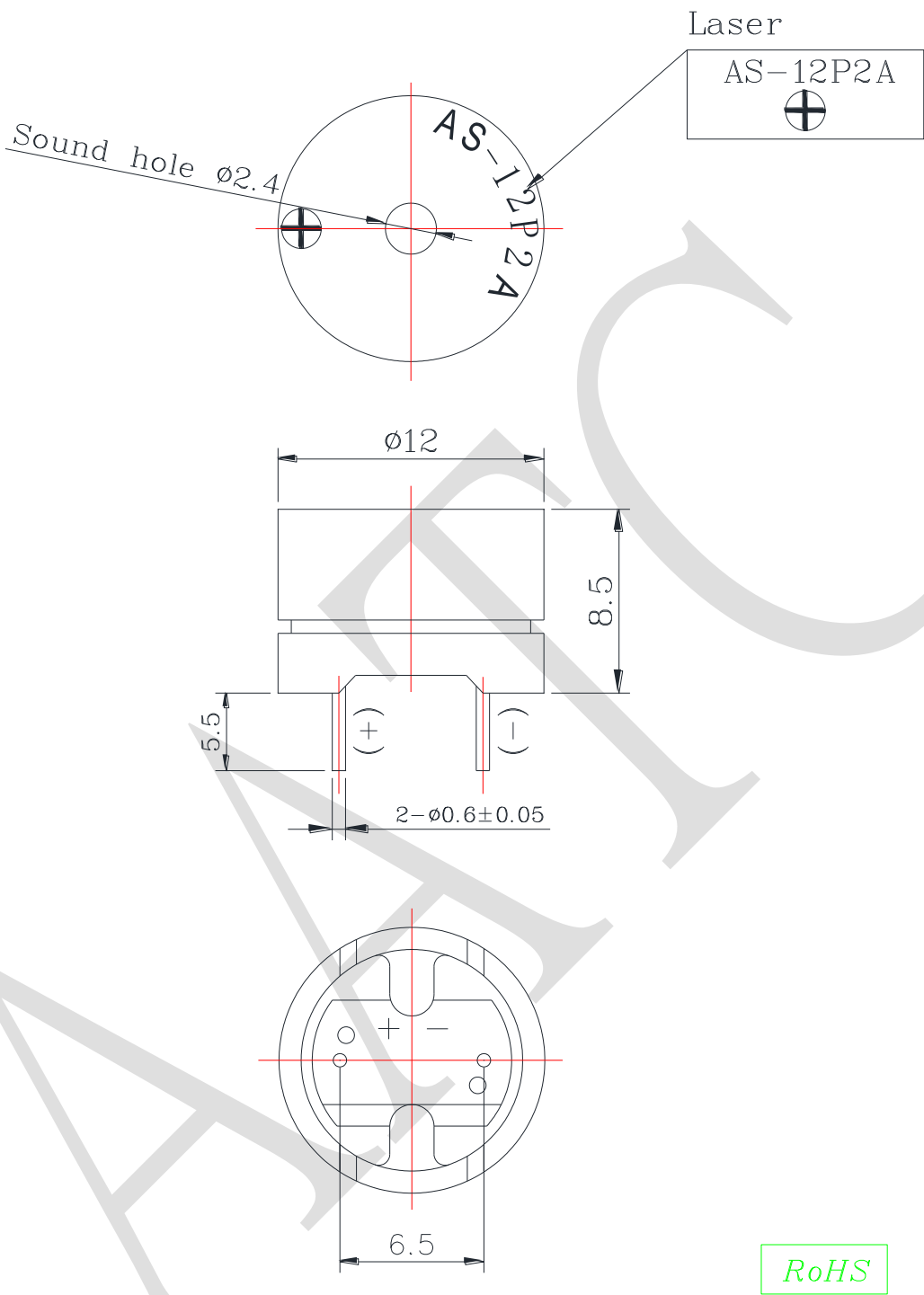


1. SPECIFICATION

AS-12P2A

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	1.5	<div>A square wave diagram with three pulses. The peak-to-peak voltage is labeled Vp-p and the low level is labeled 0V.</div> <div>Standard state, standard drive circuit. Square wave 1/2 duty.</div>
02	Operating Voltage	V	1.0 ~ 3.0	
03	Consumption Current	mA Max.	35	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	85	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	16±2.4	
06	Rated Frequency	Hz	2048	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



TITLE: ELECTRO MAGNETIC BUZZER		DRAWN: Hank	2020-1-8	SCALE: 4:1	SHEET: 1 of 1
PART NO. AS-12P2A		DESIGNED: R&D OF AAT		UNITS: mm	
DWG NO. ****		CHECKED:		TOLERANCE $\pm 0.5$	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: NORYL		ONE PLACE DECIMAL $\pm$ ***	
				TWO PLACE DECIMAL $\pm$ ***	
				THREE PLACE DECIMAL $\pm$ ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AS-903Q-LF](#) [AS-12P2A](#)