


1. SPECIFICATION

AS-9G3C



ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3	<div><p>Standard state, standard drive circuit. Square wave 1/2 duty.</p></div>
02	Operating Voltage	V	2 ~ 4.2	
03	Consumption Current	mA Max.	150	
04	Sound pressure level (Distance at 10cm )	dB(A) Min.	93	Rated voltage, rated frequency.
05	Direct Current Resistance	Ω	8±1.2	
06	Rated Frequency	Hz	2730	

REV NO.




REVISION NOTE

APPROVAL

DATE

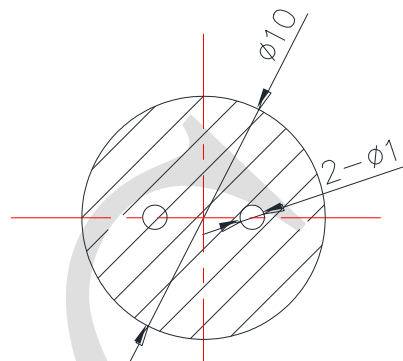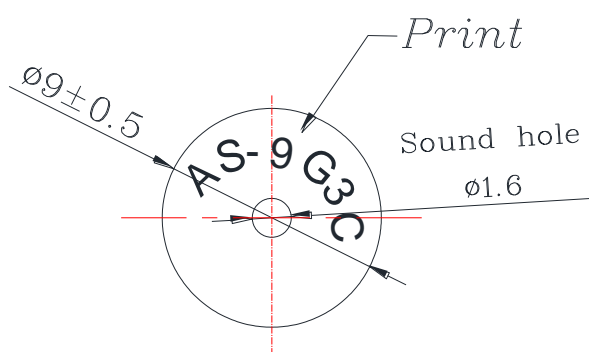

RECOMMEND PCB LAYOUT

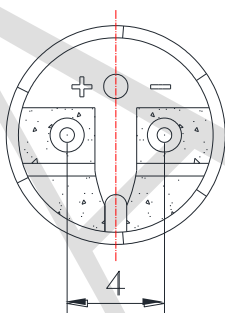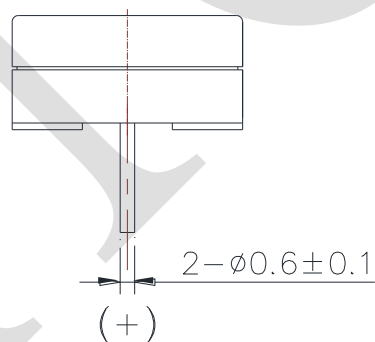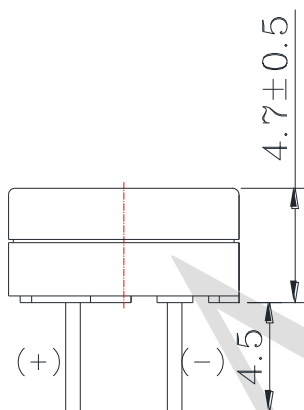

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Hank 2020/03/05

SCALE: 4:1 SHEET: 1 of 1

PART NO. AS-9G3C

DESIGNED: R&amp;D OF AAT

UNITS: mm

DWG NO. JM90473E8P

CHECKED:

TOLERANCE  $\pm 0.5$ 

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

REV 1

MATERIAL: PPO

ONE PLACE DECIMAL  $\pm$  \*\*\*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\*

ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)  
[AS-9G3C](#)