
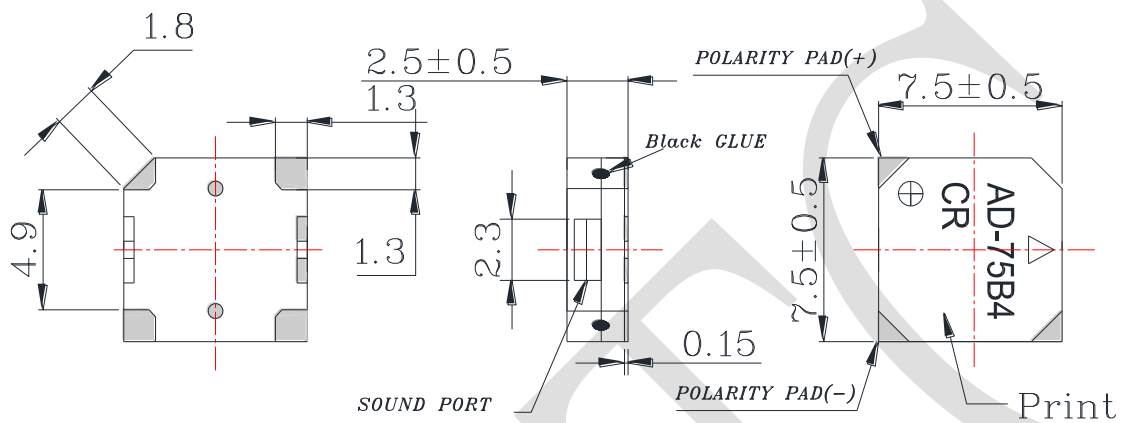


1. SPECIFICATION


AD-75B4CR

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.6	 <p>Standard state, standard drive circuit. Square wave 1/2 duty.</p>
02	Operating Voltage	V	2.5 ~ 4.5	
03	Consumption Current	mA Max.	100	
04	Sound pressure level (Distance at 5 cm)	dB(A) Min.	85	Rated voltage, rated frequency.
05	Sound pressure level (Distance at 10 cm)	dB(A) Min.	82	Rated voltage, rated frequency.
06	Direct Current Resistance	Ω	15 \pm 3	
07	Rated Frequency	Hz	2730	

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------



RECOMMENDED P.C.B LAYOUT

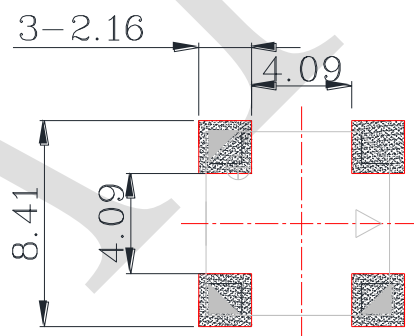

RoHS

TITLE: SOUND TRANSDUCER (SMD)		DRAWN: Zack	2020/02/10	SCALE: 1:1	SHEET: 1 : 1
PART NO. AD-75B4CR		DESIGNED: R & D OF AAT		UNITS: mm	
DWG NO. SMD-075025H-03627R15		CHECKED:		TOLERANCE ± 0.5	
		APPROVAL:		UNLESS OTHERWISE SPECIFIED:	
		MATERIAL: LCP		ONE PLACE DECIMAL ± ***	
	3			TWO PLACE DECIMAL ± ***	
	REV			THREE PLACE DECIMAL ± ***	



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AD-75B4CR](#)