 


1. SPECIFICATION

AC-1204A-RP


ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	3.5	
02	Operating Voltage	V	2 ~ 5	
03	Consumption Current	mA (Max)	Mean : 70	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
			Peak : 210	
04	Direct Current Resistance	Ω	16±3	
05	Sound pressure level (Distance at 10cm)	dBA (Min)	85	Applying rated voltage, rated frequency Square wave, 1/2 duty subject to standard state.
06	Rated Frequency	Hz	2731	

REV NO.

REVISION NOTE

APPROVAL

DATE

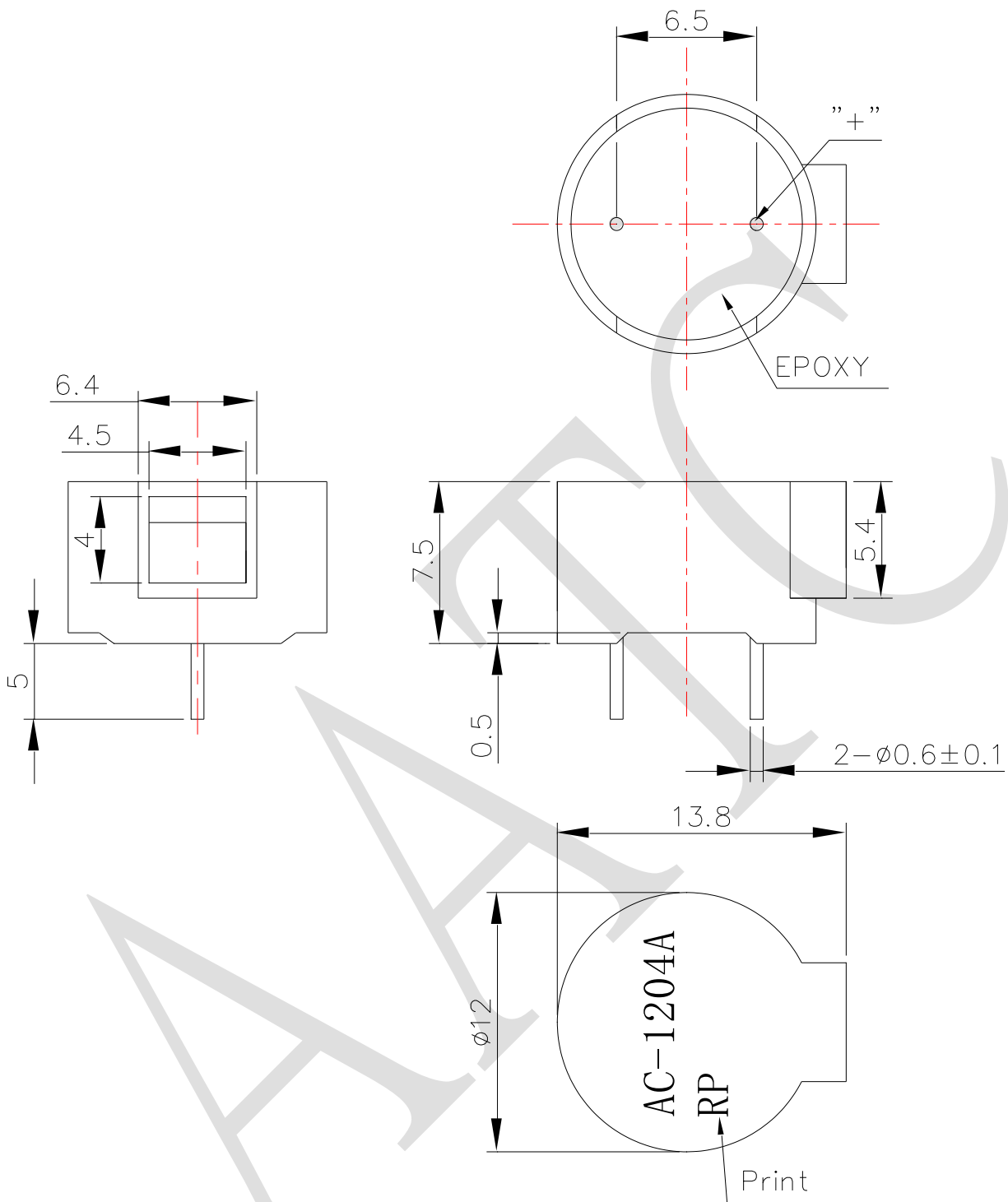

RoHS

TITLE: ELECTRO MAGNETIC BUZZER

DRAWN: Jerry 2012/08/06

SCALE: 4:1 SHEET: 1 of 1

PART NO. AC-1204A-RP

DESIGNED: R&D OF AAT

UNITS: mm

DWG NO. UGCM04BPD-3.5VR16

2

CHECKED:

TOLERANCE ± 0.3

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL ± ***

TWO PLACE DECIMAL ± ***

THREE PLACE DECIMAL ± ***

REV

MATERIAL: NORYL



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AC-1204A-RP](#)