


1. SPECIFICATION

AZ-1240E-1P

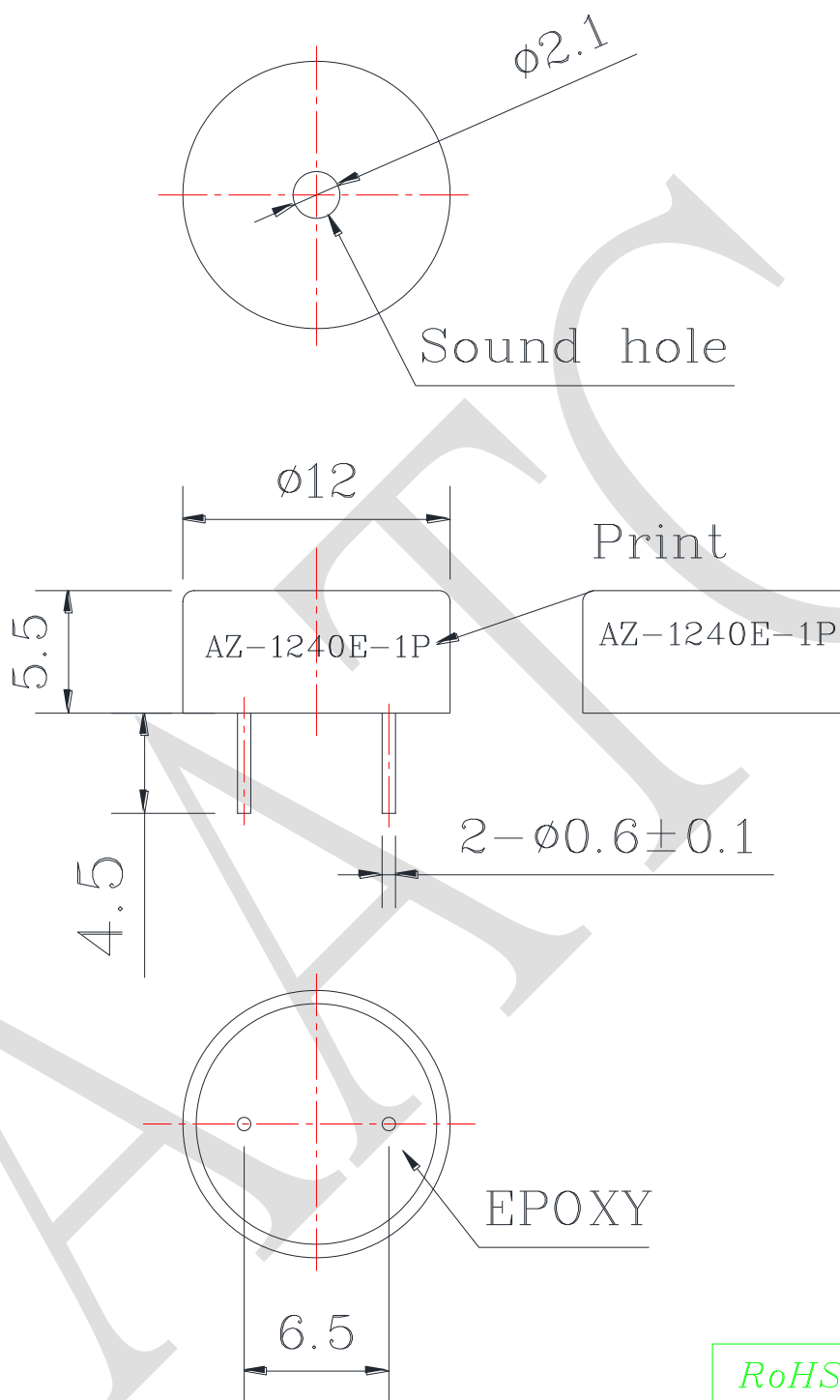
ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	9	 Square wave 1/2 duty.
02	Operating Voltage	V	1 ~ 20	
03	Consumption Current	mA (Max)	9	
04	Sound pressure level (Distance at 10cm )	dB(A) (Min)	83	Rated voltage, rated frequency.
05	Capacitance	pF	12000±30%	At 120Hz
06	Rated Frequency	Hz	4000± 300	

REV NO.

REVISION NOTE

APPROVAL

DATE

TITLE: *PIEZO BUZZER*DRAWN: **Zack**

2020/02/18

SCALE: 2:1

SHEET: 1:1

PART NO. *AZ-1240E-1P*DESIGNED: *R&D OF AAT*UNITS: *mm*

3

CHECKED:

TOLERANCE  $\pm 0.5$ DWG NO. *LPT1255-T0-09-4.0-12-6.5-R*

APPROVAL:

UNLESS OTHERWISE SPECIFIED:

ONE PLACE DECIMAL  $\pm$  \*\*\*

REV

MATERIAL: *PPO*TWO PLACE DECIMAL  $\pm$  \*\*\*THREE PLACE DECIMAL  $\pm$  \*\*\***ADVANCED ACOUSTIC TECHNOLOGY CORPORATION**

For more information, please contact AATC.

AATC

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AATC:](#)

[AZ-1240E-1P](#)