 
 



1. SPECIFICATION

AZI-1440S-3PV1

ITEM		UNITS	SPECIFICATIONS	CONDITIONS
01	Rated Voltage	V	12	
02	Operating Voltage	V	3.5~ 16	
03	Consumption Current	mA (Max)	15	Rated Voltage
04	Resonant Frequency	Hz	4000± 500	Rated Voltage
05	Response times	ms	≥ 100	
06	Sound pressure level	dB(A) Min.	85	Distance at 10cm Rated Voltage / Resonant Frequency

REV NO.	REVISION NOTE	APPROVAL	DATE
---------	---------------	----------	------

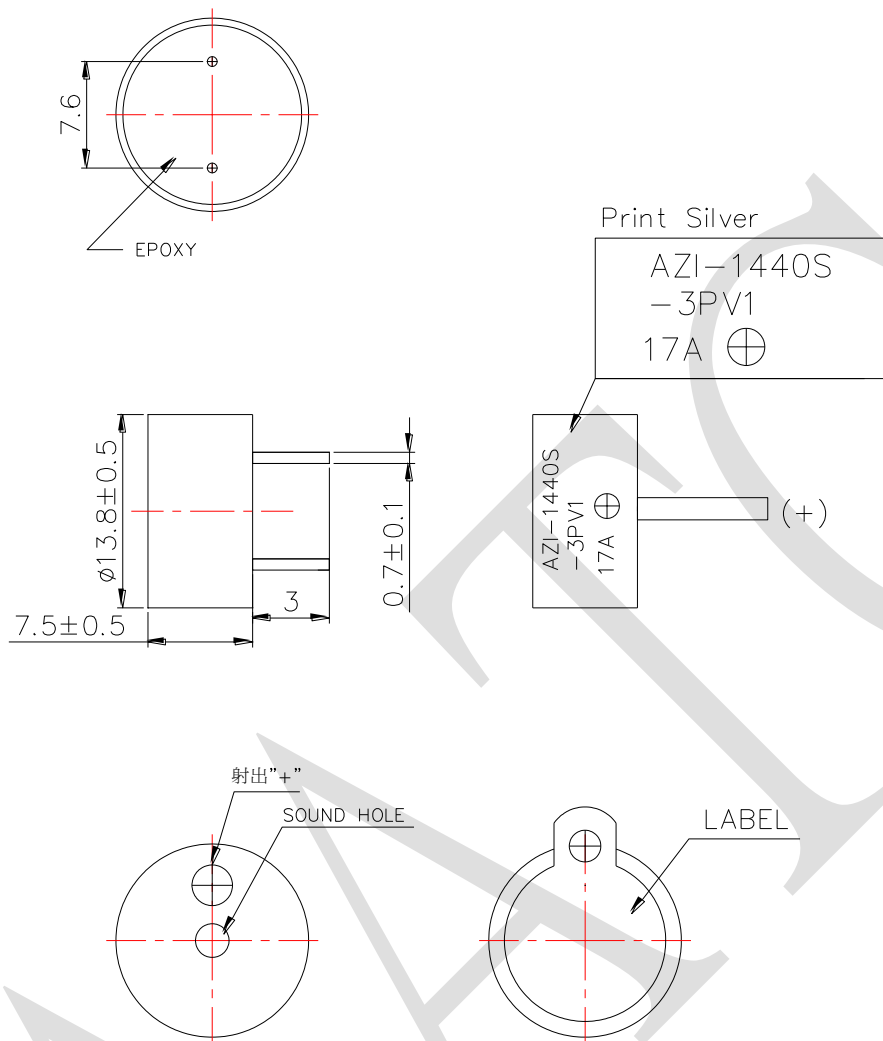

RoHS

TITLE:	PIEZO BUZZER	DRAWN:	Moose	2017-12-12	SCALE:	2:1	SHEET:	1 of 1
PART NO.	AZI-1440S-3PV1	DESIGNED:	R & D OF AAT		UNITS:	mm		
DWG NO.	LPB1475E-T0-12-4.0-7.6-R-3.0	CHECKED:			TOLERANCE	± 0.3		
		APPROVAL:			UNLESS OTHERWISE SPECIFIED:			
		MATERIAL:	PPO		ONE PLACE DECIMAL ± ***			
					TWO PLACE DECIMAL ± ***			
					THREE PLACE DECIMAL ± ***			



ADVANCED ACOUSTIC TECHNOLOGY CORPORATION

For more information, please contact AATC.

AATC

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AATC:

[AZI-1440S-3PV1](#)